

## APY EXTERNAL HORIZONTAL WALL BRACKET



### FEATURES

Side mount saddle support for C-Profiles and strut

Complete with fixings

### SPECIFICATIONS

**Finish:** Electrogalvanized

Table 1/2


| Catalog Number | Article Number | Material                           | Channel Type | Strut Type                        | Height (H) | Width (W) |
|----------------|----------------|------------------------------------|--------------|-----------------------------------|------------|-----------|
| APYE01EG       | 584758         | Steel                              | E0L, E0, E1  |                                   | 40 mm      | 124 mm    |
| APYE23EG       | 584740         | Steel                              | E2L, E2, E3  |                                   | 40 mm      | 124 mm    |
| APYE4STRUTEG   | 584751         | Steel                              | E4           | A (41 x 41 mm),<br>C (21 x 41 mm) | 50 mm      | 144 mm    |
| APYSTRUTS6     | 584840         | Stainless Steel<br>316 (EN 1.4401) |              | A (41 x 41 mm),<br>C (21 x 41 mm) | 50 mm      | 144 mm    |

Table 2/2

| Catalog Number | Article Number | Thickness (T) | A     | B     | C     |
|----------------|----------------|---------------|-------|-------|-------|
| APYE01EG       | 584758         | 5 mm          | 31 mm | 12 mm | 19 mm |
| APYE23EG       | 584740         | 5 mm          | 36 mm | 12 mm | 19 mm |
| APYE4STRUTEG   | 584751         | 5 mm          | 43 mm | 12 mm | 19 mm |

| CatalogNumber | Article Number | Thickness (T) | A     | B     | C     |
|---------------|----------------|---------------|-------|-------|-------|
| APYSTRUTS6    | 584840         | 5 mm          | 43 mm | 12 mm | 19 mm |

### DIAGRAMS

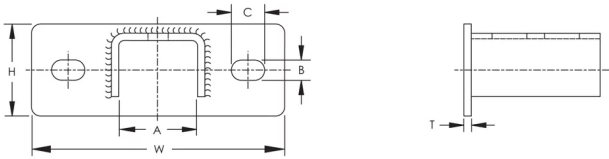

### WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

|                                                                                                     |                                                                                |                                                                                |                                                                                |
|-----------------------------------------------------------------------------------------------------|--------------------------------------------------------------------------------|--------------------------------------------------------------------------------|--------------------------------------------------------------------------------|
| <b>North America</b><br>+1.800.753.9221<br>Option 1 – Customer Care<br>Option 2 – Technical Support | <b>Europe</b><br>Netherlands:<br>+31 800-0200135<br>France:<br>+33 800 901 793 | <b>Europe</b><br>Germany:<br>800 1890272<br>Other Countries:<br>+31 13 5835404 | <b>APAC</b><br>Shanghai:<br>+ 86 21 2412 1618/19<br>Sydney:<br>+61 2 9751 8500 |
|-----------------------------------------------------------------------------------------------------|--------------------------------------------------------------------------------|--------------------------------------------------------------------------------|--------------------------------------------------------------------------------|