



NVENT CADDY SPEED LINK LIGHT PACK WITH WEDGE ANCHOR



The nVent CADDY Speed Link Light Pack with Wedge Anchor includes a precut length of 1mm wire rope riveted to a wedge anchor together with an ultra-low-profile locking device. Contractors can quickly and safely install it to the concrete ceiling to support and secure lighting and signage.

FEATURES

Complete system includes wire, locking device and wedge anchor from fischerwerke GmbH &Co. KG

Quickly and easily attaches into cracked and non-cracked concrete

No special tools required

ETA 06/0175 approval available from fischerwerke GmbH &Co. KG

SPECIFICATIONS

Static Load Safety Factor:	5:1
Material:	Steel;Brass
Finish:	Electrogalvanized

Table 1/2

Catalog Number	Article Number	Wire Rope Diameter	Wire Rope Length	Length (L)	Height (H)	Width (W)
CLP1L1WA6	196093	1 mm	1m	54 mm	17 mm	12.5 mm
CLP1L2WA6	196094	1 mm	2m	54 mm	17 mm	12.5 mm


Table 2/2

Catalog Number	Article Number	Thickness (T)	Angle (a)	Static Load (F)
CLP1L1WA6	196093	6.5 mm	60 °	100N
CLP1L2WA6	196094	6.5 mm	60 °	100N

Drill Bit Diameter: 6mm

Drill Hole Depth: 31mm
Embedment Depth: 25 mm Min

DIAGRAMS

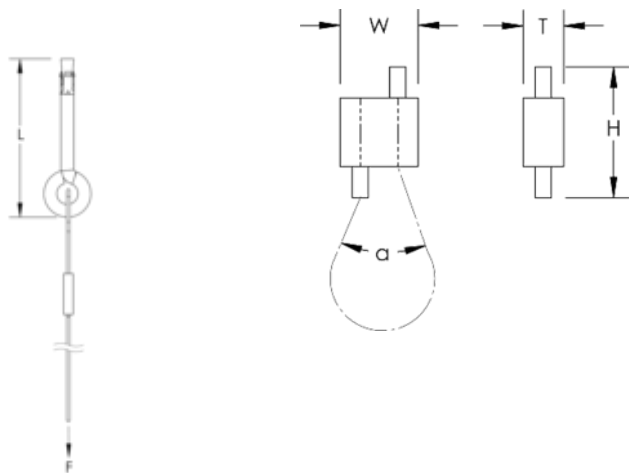

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America +1.800.753.9221 Option 1 – Customer Care Option 2 – Technical Support	Europe Netherlands: +31 800-0200135 France: +33 800 901 793	Europe Germany: 800 1890272 Other Countries: +31 13 5835404	APAC Shanghai: + 86 21 2412 1618/19 Sydney: +61 2 9751 8500
---	--	--	--



Our powerful portfolio of brands:
nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF
TRACER