

## RUBBER PROFILE FOR C-CHANNEL



### FEATURES

EPDM insulation profile to prevent contact between support and ventilation duct

For use with C-Profiles

Can be used with threaded rods up to M10

### SPECIFICATIONS


Table 1/2

Catalog Number	Article Number	Material	Temperature	Channel Type	Length (L)	Height (H)
ISOE01	400914	EPDM-SBR Rubber	-50 to 110 °C	E0, E0L, E1, E2, E2L, E3, E4	30 m	6 mm

Table 2/2

Catalog Number	Article Number	Width (W)	Hole Size (HS)
ISOE01	400914	31 mm	8.5 mm

DIAGRAMS

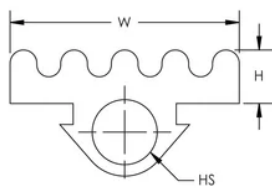

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221  
Option 1 – Customer Care  
Option 2 – Technical Support

Europe

Netherlands:  
+31 800-0200135  
France:  
+33 800 901 793

Europe

Germany:  
800 1890272  
Other Countries:  
+31 13 5835404

APAC

Shanghai:  
+ 86 21 2412 1618/19  
Sydney:  
+61 2 9751 8500



Our powerful portfolio of brands:  
**nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF**  
**TRACER**