

19" FRONT PANEL

Front panels are Al anodized, colours light grey (RAL 7035) or black grey (RAL 7021).



CERTIFICATIONS



VLASTNOSTI

Al anodized, 3 mm

SPECIFIKACE

Accessory Type: Front panel

Table 1/3

Katalogové číslo	Typ	Mounting	Front Finish	Rear Finish	Treated Edges	EMC Shielding
30118-299	19" Front Panel	Screw-on Front	Painted	Painted		No
30118-948	19" Front Panel	Screw-on Front	Painted	Painted		No
30219-098	19" Front Panel	Screw-on Front	Anodized	Anodized	No	No
40304-074	19" Front Panel	Screw-on Front	Anodized	Anodized	Yes	No
30118-301	19" Front Panel	Screw-on Front	Painted	Painted		No
30118-302	19" Front Panel	Screw-on Front	Painted	Painted		No
30118-303	19" Front Panel	Screw-on Front	Painted	Painted		No

Katalogové číslo	Typ	Mounting	Front Finish	Rear Finish	Treated Edges	EMC Shielding
30118-304	19" Front Panel	Screw-on Front	Painted	Painted		No
30118-305	19" Front Panel	Screw-on Front	Painted	Painted		No
30118-306	19" Front Panel	Screw-on Front	Painted	Painted		No
30118-307	19" Front Panel	Screw-on Front	Painted	Painted		No
30118-308	19" Front Panel	Screw-on Front	Painted	Painted		No
30118-309	19" Front Panel	Screw-on Front	Painted	Painted		No
30118-949	19" Front Panel	Screw-on Front	Painted	Painted		No
30118-950	19" Front Panel	Screw-on Front	Painted	Painted		No
30118-951	19" Front Panel	Screw-on Front	Painted	Painted		No
30118-952	19" Front Panel	Screw-on Front	Painted	Painted		No
30118-953	19" Front Panel	Screw-on Front	Painted	Painted		No
30118-954	19" Front Panel	Screw-on Front	Painted	Painted		No
30118-955	19" Front Panel	Screw-on Front	Painted	Painted		No
30118-956	19" Front Panel	Screw-on Front	Painted	Painted		No
30118-957	19" Front Panel	Screw-on Front	Painted	Painted		No
30219-101	19" Front Panel	Screw-on Front	Anodized	Anodized	No	No
30219-104	19" Front Panel	Screw-on Front	Anodized	Anodized	No	No
30219-107	19" Front Panel	Screw-on Front	Anodized	Anodized	No	No
30219-110	19" Front Panel	Screw-on Front	Anodized	Anodized	No	No
30219-113	19" Front Panel	Screw-on Front	Anodized	Anodized	No	No
30219-137	19" Front Panel	Screw-on Front	Anodized	Anodized	No	No
30219-138	19" Front Panel	Screw-on Front	Anodized	Anodized	No	No
30219-143	19" Front Panel	Screw-on Front	Anodized	Anodized	No	No
30219-144	19" Front Panel	Screw-on Front	Anodized	Anodized	No	No
40304-075	19" Front Panel	Screw-on Front	Anodized	Anodized	Yes	No
40304-076	19" Front Panel	Screw-on Front	Anodized	Anodized	Yes	No
40304-077	19" Front Panel	Screw-on Front	Anodized	Anodized	Yes	No
40304-078	19" Front Panel	Screw-on Front	Anodized	Anodized	Yes	No
40304-079	19" Front Panel	Screw-on Front	Anodized	Anodized	Yes	No
40304-080	19" Front Panel	Screw-on Front	Anodized	Anodized	Yes	No
40304-081	19" Front Panel	Screw-on Front	Anodized	Anodized	Yes	No
40304-082	19" Front Panel	Screw-on Front	Anodized	Anodized	Yes	No
40304-083	19" Front Panel	Screw-on Front	Anodized	Anodized	Yes	No

Table 2/3

Katalogové číslo	Rack Width	Product Type	Výška (H)	Works With	Rack Height	Množství v balení
30118-299	95HP	Front Panel	43.6mm	Cabinet, Wallmount Cases, 19" cases	1U	1
30118-948	95HP	Front Panel	43.6mm	Cabinet, Wallmount Cases, 19" cases	1U	1
30219-098	95HP	Front Panel	43.6mm	Cabinet, Wallmount Cases, 19" cases	1U	1
40304-074	95HP	Front Panel	43.6mm	Cabinet, Wallmount Cases, 19" cases	1U	1
30118-301	95HP	Front Panel	88.1mm	Cabinet, Wallmount Cases, 19" cases	2U	1
30118-302	95HP	Front Panel	132.5mm	Cabinet, Wallmount Cases, 19" cases	3U	1
30118-303	95HP	Front Panel	177mm	Cabinet, Wallmount Cases, 19" cases	4U	1
30118-304	95HP	Front Panel	221.4mm	Cabinet, Wallmount Cases, 19" cases	5U	1
30118-305	95HP	Front Panel	265.9mm	Cabinet, Wallmount Cases, 19" cases	6U	1
30118-306	95HP	Front Panel	310.3mm	Cabinet, Wallmount Cases, 19" cases	7U	1
30118-307	95HP	Front Panel	354.8mm	Cabinet, Wallmount Cases, 19" cases	8U	1

Katalogové číslo	Rack Width	ProductType	Výška (H)	Works With	Rack Height	Množství v balení
30118-308	95HP	Front Panel	399.2mm	Cabinet, Wallmount Cases, 19" cases	9U	1
30118-309	95HP	Front Panel	443.7mm	Cabinet, Wallmount Cases, 19" cases	10U	1
30118-949	95HP	Front Panel	88.1mm	Cabinet, Wallmount Cases, 19" cases	2U	1
30118-950	95HP	Front Panel	132.5mm	Cabinet, Wallmount Cases, 19" cases	3U	1
30118-951	95HP	Front Panel	177mm	Cabinet, Wallmount Cases, 19" cases	4U	1
30118-952	95HP	Front Panel	221.4mm	Cabinet, Wallmount Cases, 19" cases	5U	1
30118-953	95HP	Front Panel	265.9mm	Cabinet, Wallmount Cases, 19" cases	6U	1
30118-954	95HP	Front Panel	310.3mm	Cabinet, Wallmount Cases, 19" cases	7U	1
30118-955	95HP	Front Panel	354.8mm	Cabinet, Wallmount Cases, 19" cases	8U	1
30118-956	95HP	Front Panel	399.2mm	Cabinet, Wallmount Cases, 19" cases	9U	1
30118-957	95HP	Front Panel	443.7mm	Cabinet, Wallmount Cases, 19" cases	10U	1

Katalogové číslo	Rack Width	ProductType	Výška (H)	Works With	Rack Height	Množství v balení
30219-101	95HP	Front Panel	88.1mm	Cabinet, Wallmount Cases, 19" cases	2U	1
30219-104	95HP	Front Panel	132.5mm	Cabinet, Wallmount Cases, 19" cases	3U	1
30219-107	95HP	Front Panel	177mm	Cabinet, Wallmount Cases, 19" cases	4U	1
30219-110	95HP	Front Panel	221.4mm	Cabinet, Wallmount Cases, 19" cases	5U	1
30219-113	95HP	Front Panel	265.9mm	Cabinet, Wallmount Cases, 19" cases	6U	1
30219-137	95HP	Front Panel	310.3mm	Cabinet, Wallmount Cases, 19" cases	7U	1
30219-138	95HP	Front Panel	354.8mm	Cabinet, Wallmount Cases, 19" cases	8U	1
30219-143	95HP	Front Panel	399.2mm	Cabinet, Wallmount Cases, 19" cases	9U	1
30219-144	95HP	Front Panel	443.7mm	Cabinet, Wallmount Cases, 19" cases	10U	1
40304-075	95HP	Front Panel	88.1mm	Cabinet, Wallmount Cases, 19" cases	2U	1
40304-076	95HP	Front Panel	132.5mm	Cabinet, Wallmount Cases, 19" cases	3U	1

Katalogové číslo	Rack Width	ProductType	Výška (H)	Works With	Rack Height	Množství v balení
40304-077	95HP	Front Panel	177mm	Cabinet, Wallmount Cases, 19" cases	4U	1
40304-078	95HP	Front Panel	221.4mm	Cabinet, Wallmount Cases, 19" cases	5U	1
40304-079	95HP	Front Panel	265.9mm	Cabinet, Wallmount Cases, 19" cases	6U	1
40304-080	95HP	Front Panel	310.3mm	Cabinet, Wallmount Cases, 19" cases	7U	1
40304-081	95HP	Front Panel	354.8mm	Cabinet, Wallmount Cases, 19" cases	8U	1
40304-082	95HP	Front Panel	399.2mm	Cabinet, Wallmount Cases, 19" cases	9U	1
40304-083	95HP	Front Panel	443.7mm	Cabinet, Wallmount Cases, 19" cases	10U	1


Table 3/3						
Katalogové číslo	Povrchová úprava	Materiál	Barva	Kód barvy	Šířka (W)	Hloubka (D)
30118-299	Powder Coated	Aluminum	Light Grey	RAL 7035	483mm	3mm
30118-948	Powder Coated	Aluminum	Black Grey	RAL 7021	483mm	3mm
30219-098	Anodized	Aluminum			483mm	3mm
40304-074	Anodized	Aluminum			483mm	4mm
30118-301	Powder Coated	Aluminum	Light Grey	RAL 7035	483mm	3mm
30118-302	Powder Coated	Aluminum	Light Grey	RAL 7035	483mm	3mm
30118-303	Powder Coated	Aluminum	Light Grey	RAL 7035	483mm	3mm
30118-304	Powder Coated	Aluminum	Light Grey	RAL 7035	483mm	3mm
30118-305	Powder Coated	Aluminum	Light Grey	RAL 7035	483mm	3mm
30118-306	Powder Coated	Aluminum	Light Grey	RAL 7035	483mm	3mm

Katalogové číslo	Povrchová úprava	Materiál	Barva	Kód barvy	Šířka (W)	Hloubka (D)
30118-307	Powder Coated	Aluminum	Light Grey	RAL 7035	483mm	3mm
30118-308	Powder Coated	Aluminum	Light Grey	RAL 7035	483mm	3mm
30118-309	Powder Coated	Aluminum	Light Grey	RAL 7035	483mm	3mm
30118-949	Powder Coated	Aluminum	Black Grey	RAL 7021	483mm	3mm
30118-950	Powder Coated	Aluminum	Black Grey	RAL 7021	483mm	3mm
30118-951	Powder Coated	Aluminum	Black Grey	RAL 7021	483mm	3mm
30118-952	Powder Coated	Aluminum	Black Grey	RAL 7021	483mm	3mm
30118-953	Powder Coated	Aluminum	Black Grey	RAL 7021	483mm	3mm
30118-954	Powder Coated	Aluminum	Black Grey	RAL 7021	483mm	3mm
30118-955	Powder Coated	Aluminum	Black Grey	RAL 7021	483mm	3mm
30118-956	Powder Coated	Aluminum	Black Grey	RAL 7021	483mm	3mm
30118-957	Powder Coated	Aluminum	Black Grey	RAL 7021	483mm	3mm
30219-101	Anodized	Aluminum			483mm	3mm
30219-104	Anodized	Aluminum			483mm	3mm
30219-107	Anodized	Aluminum			483mm	3mm
30219-110	Powder Coated	Aluminum			483mm	3mm
30219-113	Anodized	Aluminum			483mm	3mm
30219-137	Anodized	Aluminum			483mm	3mm
30219-138	Anodized	Aluminum			483mm	3mm
30219-143	Anodized	Aluminum			483mm	3mm
30219-144	Anodized	Aluminum			483mm	3mm
40304-075	Anodized	Aluminum			483mm	4mm
40304-076	Anodized	Aluminum			483mm	4mm
40304-077	Anodized	Aluminum			483mm	4mm
40304-078	Anodized	Aluminum			483mm	4mm
40304-079	Anodized	Aluminum			483mm	4mm
40304-080	Anodized	Aluminum			483mm	4mm
40304-081	Anodized	Aluminum			483mm	4mm
40304-082	Anodized	Aluminum			483mm	4mm
40304-083	Anodized	Aluminum			483mm	4mm

ADDITIONAL PRODUCT DETAILS

Please order 19" assembly kit separately.

DIAGRAMS

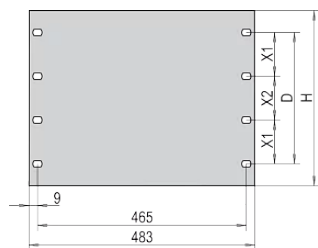

UPOZORNĚNÍ

Produkty nVent musí být instalovány a používány pouze tak, jak je uvedeno v instrukčních listech a materiálech pro školení nVent. Instrukční listy jsou k dispozici na www.nvent.com a od vašeho zástupce zákaznického servisu nVent. Nesprávná instalace, zneužití, nesprávné použití nebo jiný nedostatek úplného dodržování pokynů a varování nVent může způsobit selhání produktu, poškození majetku, vážné zranění osob a smrt a/nebo zrušit vaši záruku.



Our powerful portfolio of brands:
nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF
TRACER