


JOINT BOND T6 COMPLETE WELDER PAIR, SIGNAL, HEAD FREE BOND TERMINAL STYLE, 5/16" BONDSTRAND

KATALOGOVÉ ČÍSLO

SBHFT6B

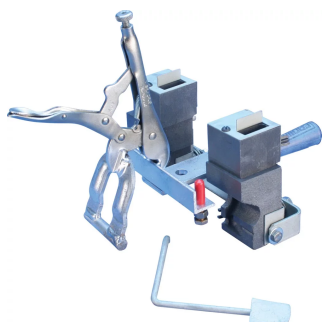

VLASTNOSTI

Complete welder assembly provides a convenient means of attaching jumper bonds to the head of the rail, across the joint

Connection is made within the confines of the splice bar

Includes mold cleaner

VLASTNOSTI PRODUKTU

Materiál: Steel; Graphite; Thermoplastic

Rail Type: 85 lb to 141 lb T-Rail Sections

Bond Terminal Style: Head Free

Conductor Size: 5/16" Bondstrand

Conductor Outer Diameter, Nominal: 7.95mm

Bond Length: 177.8mm

Welder Style: T6

Mold Only: No

Replacement Mold: SBB492M

Welding Material: SB32, Sold Separately

Bond Clip: B194D x 2, Sold Separately

UPOZORNĚNÍ

Produkty nVent musí být instalovány a používány pouze tak, jak je uvedeno v instrukčních listech a materiálech pro školení nVent. Instrukční listy jsou k dispozici na www.nvent.com a od vašeho zástupce zákaznického servisu nVent. Nesprávná instalace, zneužití, nesprávné použití nebo jiný nedostatek úplného dodržování pokynů a varování nVent může způsobit selhání produktu, poškození majetku, vážné zranění osob a smrt a/nebo zrušit vaši záruku.

⚠ WARNING: This product can expose you to chemicals including diisononyl phthalate, which is known to the State of California to cause cancer. For more information go to www.P65Warnings.ca.gov.



Our powerful portfolio of brands:
nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF
TRACER