

FOUR POLE DISTRIBUTION BLOCK WITH THREADED BARS, FLAT, 630 A

KATALOGOVÉ ČÍSLO

TRC-630A



CERTIFICATIONS



VLASTNOSTI

Transparent protection cover

Bolts included for output connections

Easy accessibility for wiring

Ready to use out of the box, saving installation time and labor

RoHS compliant

VLASTNOSTI PRODUKTU

Article Number: 563190

Materiál: Copper; Glass Fibre Reinforced Polyamide; Plexiglass

Max Working Voltage, IEC (Ui): 1000

Peak Short Circuit Current (Ipk): 84kA

Short Term Withstand Current (Icw) 1s: 52kA

Line Side Number of Connections: 1

Load Side Number of Connections: 8

Hole Size (HS): 10mm

Thread Size (TS): M8

Hloubka (D): 60mm

Height (H): 338 – 390mm

Width (W): 340mm

A: 290mm

Unit Weight: 4.8kg


Flammability Rating: UL® 94V-0

Complies With: IEC® 60439.1; IEC® 61439.1; IEC® 60695-2-11 (Glow Wire Test 960 °C)

ADDITIONAL PRODUCT DETAILS

Line side and load side number of connections are per pole.

DIAGRAMS

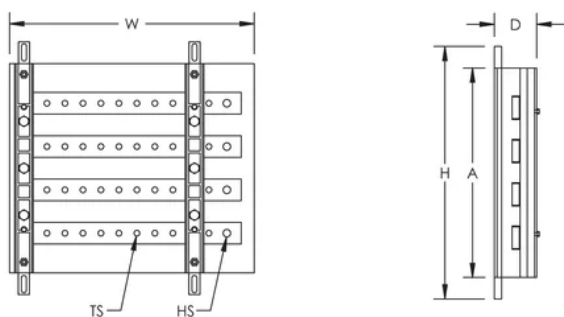

UPOZORNĚNÍ

Produkty nVent musí být instalovány a používány pouze tak, jak je uvedeno v instrukčních listech a materiálech pro školení nVent. Instrukční listy jsou k dispozici na www.nvent.com a od vašeho zástupce zákaznického servisu nVent. Nesprávná instalace, zneužití, nesprávné použití nebo jiný nedostatek úplného dodržování pokynů a varování nVent může způsobit selhání produktu, poškození majetku, vážné zranění osob a smrt a/nebo zrušit vaši záruku.



Our powerful portfolio of brands:
nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF
TRACER