


SOCKET STRIP, UTE

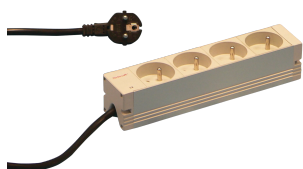

Modular, compact PDU with many function elements. Using a 1 U by 1 U aluminum chassis the PDU can easily be integrated in a rack with UTE outlets.

CERTIFICATIONS



VLASTNOSTI

230 V, 16 A

In accordance with NFC 61-303

Socket strip with UTE sockets

Mounting height 1 U

Horizontal or vertical mounting

Connecting cable 2 m, with SCHUKO/UTE plug

Socket strips can be rotated through all four directions (in 90° increments) during installation

SPECIFIKACE

Table 1/2

Katalogové číslo	Product Type	Typ zásuvky	Socket Quantity	Switched Outlets	Barva	Napětí střídavé
60110-220	Socket Strip	UTE	4	No	Grey	230V
60110-221	Socket Strip	UTE	9	No	Grey	230V
60110-222	Socket Strip	UTE	12	No	Grey	230V

Katalogové číslo	ProductType	Typ zásuvky	Socket Quantity	Switched Outlets	Barva	Napětí střídavé
60110-223	Socket Strip	UTE	15	No	Grey	230V
60110-224	Socket Strip	UTE	19	No	Grey	230V
60110-225	Socket Strip	UTE	8	Yes	Grey	230V
60110-226	Socket Strip	UTE	12	Yes	Grey	230V
60110-227	Socket Strip	UTE	8	No	Grey	230V
60110-228	Socket Strip	UTE	6	No	Grey	230V
60110-229	Socket Strip	UTE	7	No	Grey	230V
60110-230	Socket Strip	UTE	6	No	Grey	230V
60110-231	Socket Strip	UTE	6	No	Grey	230V
60110-267	Socket Strip	UTE	6	No	Grey	230V

Table 2/2						
Katalogové číslo	Function	Length	Hloubka	Povrchová úprava	Materiál	Množství v balení
60110-220		210mm	44mm	Anodized	Aluminum, Polyamide	1
60110-221		438.5mm	44mm	Anodized	Aluminum, Polyamide	1
60110-222		947.5mm	44mm	Anodized	Aluminum, Polyamide	1
60110-223		1202mm	44mm	Anodized	Aluminum, Polyamide	1
60110-224		1753mm	44mm	Anodized	Aluminum, Polyamide	1
60110-225		438.5mm	44mm	Anodized	Aluminum, Polyamide	1
60110-226		947.5mm	44mm	Anodized	Aluminum, Polyamide	1
60110-227	Transient Protection	438.5mm	44mm	Anodized	Aluminum, Polyamide	1
60110-228	Overcurrent Protection	438.5mm	75mm	Anodized	Aluminum, Polyamide	1
60110-229	Mains Suppression Filter	438.5mm	44mm	Anodized	Aluminum, Polyamide	1
60110-230	Fault Current Protection	438.5mm	88mm	Anodized	Aluminum, Polyamide	1

Katalogové číslo	Function	Length	Hloubka	Povrchová úprava	Materiál	Množství v balení
60110-231	Fault Current Protection, Overcurrent Protection	438.5mm	88mm	Anodized	Aluminum, Polyamide	1
60110-267	Transient Protection, Mains Suppression Filter	438.5mm	44mm	Anodized	Aluminum, Polyamide	1

ADDITIONAL PRODUCT DETAILS

Please order bracket for vertical mounting separately.

UPOZORNĚNÍ

Produkty nVent musí být instalovány a používány pouze tak, jak je uvedeno v instrukčních listech a materiálech pro školení nVent. Instrukční listy jsou k dispozici na www.nvent.com a od vašeho zástupce zákaznického servisu nVent. Nesprávná instalace, zneužití, nesprávné použití nebo jiný nedostatek úplného dodržování pokynů a varování nVent může způsobit selhání produktu, poškození majetku, vážné zranění osob a smrt a/nebo zrušit vaši záruku.



Our powerful portfolio of brands:
nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF
TRACER