

TELECOM MAIN GROUNDING BUSBAR



CERTIFICATIONS



VLASTNOSTI

Meets TIA-607-C and TIA-607-D and conforms to BICSI® recommendations

Complies with NEMA® standards

Accepts two hole lugs with 5/16" or 7/16" bolt holes (hardware not included)

Telecom grounding busbar splice kits are available to extend the length of the busbar

SPECIFIKACE

Thickness (T): 6.35mm
Width (W): 101.6mm
Materiál: Copper

Table 1/2


Katalogové číslo	Length 1 (L1)	Length 2 (L2)	Tin Plating	Hole Size 1 Number of Pairs	Hole Size 2 Number of Pairs	C
TMGBA12L15P	305mm	229mm	No	15	3	15.9mm
TMGBA12L15PT	305mm	229mm	Yes	15	3	15.9mm

Katalogové číslo	Length 1(L1)	Length 2(L2)	Tin Plating	Hole Size 1 Number of Pairs	Hole Size 2 Number of Pairs	C
TMGBA20L27P	508mm	229mm	No	27	3	15.9mm
TMGBA24L33PT	610mm	457mm	Yes	33	5	15.9mm
TMGBA29L41PT	737mm	457mm	Yes	41	5	15.9mm

Table 2/2

Katalogové číslo	B	A	D	Hole Size 1 (HS1)	Hole Size 2 (HS2)
TMGBA12L15P	28.6mm	25.4mm	15.9mm	0.3125in	0.4375in
TMGBA12L15PT	28.6mm	25.4mm	15.9mm	0.3125in	0.4375in
TMGBA20L27P	28.6mm	25.4mm	15.9mm	0.3125in	0.4375in
TMGBA24L33PT	28.6mm	25.4mm	15.9mm	0.3125in	0.4375in
TMGBA29L41PT	28.6mm	25.4mm	15.9mm	0.3125in	0.4375in

DIAGRAMS

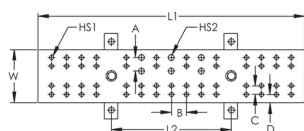

UPOZORNĚNÍ

Produkty nVent musí být instalovány a používány pouze tak, jak je uvedeno v instrukčních listech a materiálech pro školení nVent. Instrukční listy jsou k dispozici na www.nvent.com a od vašeho zástupce zákaznického servisu nVent. Nesprávná instalace, zneužití, nesprávné použití nebo jiný nedostatek úplného dodržování pokynů a varování nVent může způsobit selhání produktu, poškození majetku, vážné zranění osob a smrt a/nebo zrušit vaši záruku.



Our powerful portfolio of brands:
nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF
TRACER