


FRONT HANDLE ONE-PIECE, WIDTH 12.2 MM

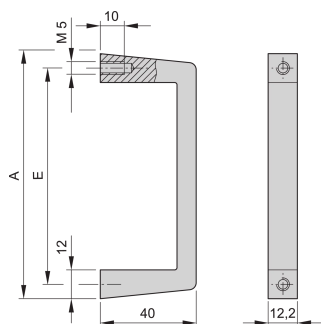

The handle can be assembled to a subrack or 19" front panel. Available with clear or black anodized surface. Handles will be bolted from the rear side.

CERTIFICATIONS



VLASTNOSTI

Static load-carrying capacity 30 kg/pair

Bolted from rear

SPECIFIKACE

Table 1/2

Katalogové číslo	Product Type	Works With	Typ rukojeti	Rack Height	Materiál	Barva
10501-116	Handle	Subracks	Straight	1U	Aluminum	Silver
10501-004	Handle	Subracks	Straight	2U	Aluminum	Silver
10501-005	Handle	Subracks	Straight	3U	Aluminum	Silver
10501-006	Handle	Subracks	Straight	4U	Aluminum	Silver
10501-007	Handle	Subracks	Straight	5U	Aluminum	Silver
10501-008	Handle	Subracks	Straight	6U	Aluminum	Silver
10501-016	Handle	Subracks	Straight	2U	Aluminum	Silver
10501-018	Handle	Subracks	Straight	4U	Aluminum	Silver

Katalogové číslo	ProductType	Works With	Typ rukojeti	Rack Height	Materiál	Barva
10501-020	Handle	Subracks	Angled Handle	3U	Aluminum	Silver
10501-021	Handle	Subracks	Angled Handle	4U	Aluminum	Silver
10501-022	Handle	Subracks	Angled Handle	6U	Aluminum	Silver
10501-025	Handle	Subracks	Straight	2U	Aluminum	Black
10501-026	Handle	Subracks	Straight	3U	Aluminum	Black
10501-027	Handle	Subracks	Straight	4U	Aluminum	Black
10501-028	Handle	Subracks	Straight	5U	Aluminum	Black
10501-029	Handle	Subracks	Straight	6U	Aluminum	Black

Table 2/2			
Katalogové číslo	Množství v balení	Povrchová úprava	Torque
10501-116	1	Anodized	
10501-004	1	Anodized	
10501-005	1	Anodized	2.4N·m
10501-006	1	Anodized	
10501-007	1	Anodized	
10501-008	1	Anodized	2.4N·m
10501-016	1	Anodized	
10501-018	1	Anodized	2.4N·m
10501-020	1	Anodized	2.4N·m
10501-021	1	Anodized	2.4N·m
10501-022	1	Anodized	2.4N·m
10501-025	1	Anodized	
10501-026	1	Anodized	2.4N·m
10501-027	1	Anodized	
10501-028	1	Anodized	
10501-029	1	Anodized	2.4N·m

ADDITIONAL PRODUCT DETAILS

Please order assembly part kit separately.

Please take into consideration that deliveries may be carried out in the stated SPQs (SPQ, e.g. 5 pieces, 10 pieces, 50 pieces, etc.). Differing order quantities (e.g. 2 pieces) may be changed to the next possible delivery quantity = Standard Pack Quantity.

UPOZORNĚNÍ

Produkty nVent musí být instalovány a používány pouze tak, jak je uvedeno v instrukčních listech a materiálech pro školení nVent. Instrukční listy jsou k dispozici na www.nvent.com a od vašeho zástupce zákaznického servisu nVent. Nesprávná instalace, zneužití, nesprávné použití nebo jiný nedostatek úplného dodržování pokynů a varování nVent může způsobit selhání produktu, poškození majetku, vážné zranění osob a smrt a/nebo zrušit vaši záruku.

North America

All locations
+1.763.422.2661
Chat with us:
schroff.nvent.com

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
schroff.nvent.com

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
schroff.nvent.com

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
schroff.nvent.com



Our powerful portfolio of brands:
nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF
TRACER