


FRONT PANEL, UNSHIELDED, BOTTOM HINGED

Unshielded front panel bottom hinged.

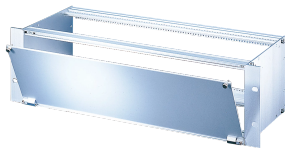

CERTIFICATIONS



MERKMALE

Front panel can be unhinged at 135° (not RatiopacPRO) opening angle

Enables mounting on horizontal rails

SPEZIFIKATIONEN

Table 1/3

Katalognummer	Treated Edges	Front Finish	Rear Finish	EMC Shielding	Rack Width	Package Quantity
20838-271	Nein	Anodized	Conductive	Nein	42 HP	1
20838-272	Nein	Anodized	Conductive	Nein	63 HP	1
20838-273	Nein	Anodized	Conductive	Nein	84 HP	1
20838-274	Nein	Anodized	Conductive	Nein	42 HP	1
20838-275	Nein	Anodized	Conductive	Nein	63 HP	1
20838-276	Nein	Anodized	Conductive	Nein	84 HP	1
20838-277	Nein	Anodized	Conductive	Nein	42 HP	1
20838-278	Nein	Anodized	Conductive	Nein	63 HP	1

Katalognummer	Treated Edges	Front Finish	Rear Finish	EMC Shielding	Rack Width	Package Quantity
20838-279	Nein	Anodized	Conductive	Nein	84 HP	1
20838-280	Nein	Anodized	Conductive	Nein	28 HP	1

Table 2/3						
Katalognummer	Höhe	Product Type	Typ	Rack Height	Breite	Konform mit
20838-271	128.4 mm	Frontplatte	Front Panel without Handle	3 U	213 mm	IEC 60297-3-101, IEEE 1101.1/10
20838-272	128.4 mm	Frontplatte	Front Panel without Handle	3 U	319.7 mm	IEC 60297-3-101, IEEE 1101.1/10
20838-273	128.4 mm	Frontplatte	Front Panel without Handle	3 U	426.4 mm	IEC 60297-3-101, IEEE 1101.1/10
20838-274	261.8 mm	Frontplatte	Front Panel without Handle	6 U	213 mm	IEC 60297-3-101, IEEE 1101.1/10
20838-275	261.8 mm	Frontplatte	Front Panel without Handle	6 U	319.7 mm	IEC 60297-3-101, IEEE 1101.1/10
20838-276	261.8 mm	Frontplatte	Front Panel without Handle	6 U	426.4 mm	IEC 60297-3-101, IEEE 1101.1/10
20838-277	172.9 mm	Frontplatte	Front Panel without Handle	4 U	213 mm	IEC 60297-3-101, IEEE 1101.1/10
20838-278	172.9 mm	Frontplatte	Front Panel without Handle	4 U	319.7 mm	IEC 60297-3-101, IEEE 1101.1/10
20838-279	172.9 mm	Frontplatte	Front Panel without Handle	4 U	426.4 mm	IEC 60297-3-101, IEEE 1101.1/10
20838-280	128.4 mm	Frontplatte	Front Panel without Handle	3 U	141.9 mm	IEC 60297-3-101, IEEE 1101.1/10

Table 3/3		
Katalognummer	Montage	Material
20838-271	Hinged, Bottom	Aluminium
20838-272	Hinged, Bottom	Aluminium
20838-273	Hinged, Bottom	Aluminium

Katalognummer	Montage	Material
20838-274	Hinged, Bottom	Aluminium
20838-275	Hinged, Bottom	Aluminium
20838-276	Hinged, Bottom	Aluminium
20838-277	Hinged, Bottom	Aluminium
20838-278	Hinged, Bottom	Aluminium
20838-279	Hinged, Bottom	Aluminium
20838-280	Hinged, Bottom	Aluminium

ADDITIONAL PRODUCT DETAILS

Front panel can be removed in opened position (> 135°).

WARNUNG

nVent-Produkte müssen in Übereinstimmung mit den Produktinformationsblättern und dem Schulungsmaterial von nVent installiert und verwendet werden. Informationsblätter sind verfügbar unter www.nVent.com sowie bei Ihrem nVent-Kundendienstvertreter. Unsachgemäße Installation, Missbrauch, Fehlanwendung oder andere Handlungen im Widerspruch zu den Anweisungen und Warnungen von nVent können zu Fehlfunktionen, Anlagenschäden, schwerer Körperverletzung sowie zum Tod führen und/oder haben die Annullierung der Garantie zur Folge.



Our powerful portfolio of brands:
nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF
TRACER