


## FRONT PANEL, UNSHIELDED, BOTTOM HINGED

Unshielded front panel bottom hinged.

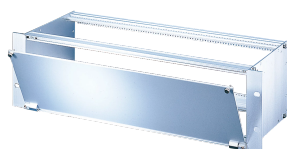

### CERTIFICATIONS



### MERKMALE

Front panel can be unhinged at 135° (not RatiopacPRO) opening angle

Enables mounting on horizontal rails

### SPEZIFIKATIONEN

Table 1/3

| Katalognummer | Treated Edges | Front Finish | Rear Finish | EMC Shielding | Rack Width | Package Quantity |
|---------------|---------------|--------------|-------------|---------------|------------|------------------|
| 20838-271     | Nein          | Anodized     | Conductive  | Nein          | 42 HP      | 1                |
| 20838-272     | Nein          | Anodized     | Conductive  | Nein          | 63 HP      | 1                |
| 20838-273     | Nein          | Anodized     | Conductive  | Nein          | 84 HP      | 1                |
| 20838-274     | Nein          | Anodized     | Conductive  | Nein          | 42 HP      | 1                |
| 20838-275     | Nein          | Anodized     | Conductive  | Nein          | 63 HP      | 1                |
| 20838-276     | Nein          | Anodized     | Conductive  | Nein          | 84 HP      | 1                |
| 20838-277     | Nein          | Anodized     | Conductive  | Nein          | 42 HP      | 1                |
| 20838-278     | Nein          | Anodized     | Conductive  | Nein          | 63 HP      | 1                |

| Katalognummer | Treated Edges | Front Finish | Rear Finish | EMC Shielding | Rack Width | Package Quantity |
|---------------|---------------|--------------|-------------|---------------|------------|------------------|
| 20838-279     | Nein          | Anodized     | Conductive  | Nein          | 84 HP      | 1                |
| 20838-280     | Nein          | Anodized     | Conductive  | Nein          | 28 HP      | 1                |

| Table 2/3     |          |              |                            |             |          |                                 |
|---------------|----------|--------------|----------------------------|-------------|----------|---------------------------------|
| Katalognummer | Höhe     | Product Type | Typ                        | Rack Height | Breite   | Konform mit                     |
| 20838-271     | 128.4 mm | Frontplatte  | Front Panel without Handle | 3 U         | 213 mm   | IEC 60297-3-101, IEEE 1101.1/10 |
| 20838-272     | 128.4 mm | Frontplatte  | Front Panel without Handle | 3 U         | 319.7 mm | IEC 60297-3-101, IEEE 1101.1/10 |
| 20838-273     | 128.4 mm | Frontplatte  | Front Panel without Handle | 3 U         | 426.4 mm | IEC 60297-3-101, IEEE 1101.1/10 |
| 20838-274     | 261.8 mm | Frontplatte  | Front Panel without Handle | 6 U         | 213 mm   | IEC 60297-3-101, IEEE 1101.1/10 |
| 20838-275     | 261.8 mm | Frontplatte  | Front Panel without Handle | 6 U         | 319.7 mm | IEC 60297-3-101, IEEE 1101.1/10 |
| 20838-276     | 261.8 mm | Frontplatte  | Front Panel without Handle | 6 U         | 426.4 mm | IEC 60297-3-101, IEEE 1101.1/10 |
| 20838-277     | 172.9 mm | Frontplatte  | Front Panel without Handle | 4 U         | 213 mm   | IEC 60297-3-101, IEEE 1101.1/10 |
| 20838-278     | 172.9 mm | Frontplatte  | Front Panel without Handle | 4 U         | 319.7 mm | IEC 60297-3-101, IEEE 1101.1/10 |
| 20838-279     | 172.9 mm | Frontplatte  | Front Panel without Handle | 4 U         | 426.4 mm | IEC 60297-3-101, IEEE 1101.1/10 |
| 20838-280     | 128.4 mm | Frontplatte  | Front Panel without Handle | 3 U         | 141.9 mm | IEC 60297-3-101, IEEE 1101.1/10 |

| Table 3/3     |                |           |
|---------------|----------------|-----------|
| Katalognummer | Montage        | Material  |
| 20838-271     | Hinged, Bottom | Aluminium |
| 20838-272     | Hinged, Bottom | Aluminium |
| 20838-273     | Hinged, Bottom | Aluminium |

| Katalognummer | Montage        | Material  |
|---------------|----------------|-----------|
| 20838-274     | Hinged, Bottom | Aluminium |
| 20838-275     | Hinged, Bottom | Aluminium |
| 20838-276     | Hinged, Bottom | Aluminium |
| 20838-277     | Hinged, Bottom | Aluminium |
| 20838-278     | Hinged, Bottom | Aluminium |
| 20838-279     | Hinged, Bottom | Aluminium |
| 20838-280     | Hinged, Bottom | Aluminium |

## ADDITIONAL PRODUCT DETAILS

Front panel can be removed in opened position (> 135°).

## WARNUNG

nVent-Produkte müssen in Übereinstimmung mit den Produktinformationsblättern und dem Schulungsmaterial von nVent installiert und verwendet werden. Informationsblätter sind verfügbar unter [www.nVent.com](http://www.nVent.com) sowie bei Ihrem nVent-Kundendienstvertreter. Unsachgemäße Installation, Missbrauch, Fehlanwendung oder andere Handlungen im Widerspruch zu den Anweisungen und Warnungen von nVent können zu Fehlfunktionen, Anlagenschäden, schwerer Körperverletzung sowie zum Tod führen und/oder haben die Annullierung der Garantie zur Folge.



Our powerful portfolio of brands:  
**nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF**  
**TRACER**