


SOCKET STRIP, IEC C19

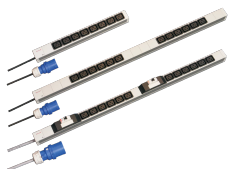

Modular, compact PDU with many function elements. Using a 1 U by 1 U aluminum chassis the PDU can easily be integrated in a rack with IEC C19 outlets.

CERTIFICATIONS



MERKMALE

Socket strips with C19 IEC sockets

Socket strips can be rotated through all four directions (in 90° increments) during installation

Connecting cable 2 m, with connector in accordance with IEC 60309

Mounting height 1 U

SPEZIFIKATIONEN

Table 1/2

Katalognummer	Wechselspannung	Höhe	Product Type	Socket Type	Tiefe	Farbe
60110-280	230 V	44 mm	Socket Strip	IEC C19	44 mm	Grau
60110-281	230 V	44 mm	Socket Strip	IEC C19	44 mm	Grau
60110-282	230 V	44 mm	Socket Strip	IEC C19	44 mm	Grau

Table 2/2

Katalognummer	Länge
60110-280	438.5 mm

Katalognummer	Länge
60110-281	947.5 mm
60110-282	947.5 mm

ADDITIONAL PRODUCT DETAILS

Please order bracket for vertical mounting separately.

WARNUNG

nVent-Produkte müssen in Übereinstimmung mit den Produktinformationsblättern und dem Schulungsmaterial von nVent installiert und verwendet werden. Informationsblätter sind verfügbar unter www.nVent.com sowie bei Ihrem nVent-Kundendienstvertreter. Unsachgemäße Installation, Missbrauch, Fehlanwendung oder andere Handlungen im Widerspruch zu den Anweisungen und Warnungen von nVent können zu Fehlfunktionen, Anlagenschäden, schwerer Körperverletzung sowie zum Tod führen und/oder haben die Annullierung der Garantie zur Folge.



Our powerful portfolio of brands:
nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF
TRACER