


FRONT PANEL ALTERNATIVE FOR COMBINED MOUNTING

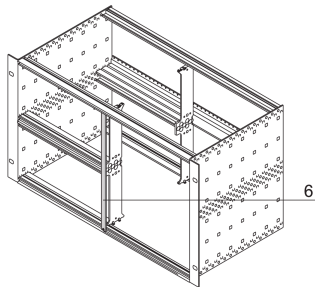

The 2 HP wide front panel covers an open slot. The U-profile front panel can be combined with a textile EMC gasket. It be fixed with screws and washers. Due to the 2 HP width no sleeves can be used.

CERTIFICATIONS



MERKMALE

U-profile front panel 6 U, 2 HP, Al, 2.5 mm

Prepared for textile EMC gasket

SPEZIFIKATIONEN

Table 1/2

Katalognummer	Treated Edges	Front Finish	Rear Finish	Package Quantity	Product Type	Product Family
30849-140	Nein	Anodized	Conductive	5	Frontplatte	EuropacPRO, RatiopacPRO, RatiopacPRO AIR, CompacPRO, PropacPRO

Table 2/2

Katalognummer	Kompatibel mit	Rack Height
30849-140	Subracks, Cases	6 U

ADDITIONAL PRODUCT DETAILS

Please take into consideration that deliveries may be carried out in the stated SPQs (SPQ, e.g. 5 pieces, 10 pieces, 50 pieces, etc.). Differing order quantities (e.g. 2 pieces) may be changed to the next possible delivery quantity = Standard Pack Quantity.

WARNUNG

nVent-Produkte müssen in Übereinstimmung mit den Produktinformationsblättern und dem Schulungsmaterial von nVent installiert und verwendet werden. Informationsblätter sind verfügbar unter www.nVent.com sowie bei Ihrem nVent-Kundendienstvertreter. Unsachgemäße Installation, Missbrauch, Fehlanwendung oder andere Handlungen im Widerspruch zu den Anweisungen und Warnungen von nVent können zu Fehlfunktionen, Anlagenschäden, schwerer Körperverletzung sowie zum Tod führen und/oder haben die Annullierung der Garantie zur Folge.



Our powerful portfolio of brands:
nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF
TRACER