



NVENT CADDY MACROFIX PLUS



CERTIFICATIONS



FEATURES

- Includes easy closing mechanism
- Age-resistant lining
- Combo head bolt works with slotted, hex, or Phillips drivers
- Category II noise reduction according to DIN EN ISO 3822-1
- Compliant for sound insulation design according to DIN 4109
- Reaction-to-fire classification is "E" in compliance with DIN EN 13501-1

SPECIFICATIONS

- Color:** Black
- Finish:** Electrogalvanized
- Material:** Steel;EPDM-SBR Rubber
- Temperature:** -50 to 110 °C

Table 1/2

Catalog Number	Article Number	Outer Diameter (OD)	Pipe Size	NB/DN	Rod Size (RS)	Width (W)
----------------	----------------	---------------------	-----------	-------	---------------	-----------

MPD014	400078	12 - 14 mm	1/4"	8	8, 10	20 mm
MPD073	400088	70 - 73 mm			8, 10	20 mm
MPD169	400099	165 - 169 mm	6"	150	8, 10	23 mm


Table 2/2

Catalog Number	Article Number	Thickness (T)	Screw Diameter (Sc)	Screw Length (L)	Static Load (F)
MPD014	400078	1.5 mm	6	20mm	1000N
MPD073	400088	2 mm	6	25mm	1300N
MPD169	400099	2.5 mm	8	30mm	2200N

ADDITIONAL PRODUCT DETAILS

Lining is EPDM rubber.

DIAGRAMS

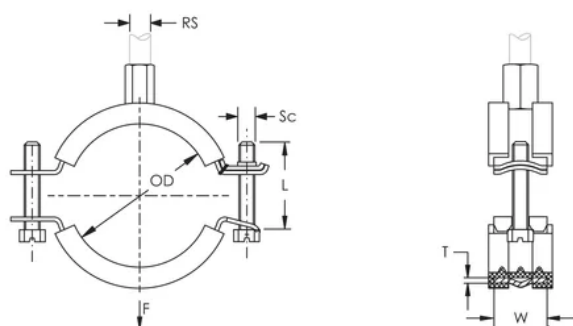

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:
nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF
TRACER