



# IMPROVED NVENT CADDY CAT HP J-HOOK MOD CLIP WITH BC BEAM CLAMP



The Improved nVent CADDY Cat HP Mod Clip J-Hook with BC Beam Clamp simplifies beam flange installation with an easy-to-use design. By eliminating the need for screws, rivets or special tools during assembly, installation time and cost is reduced. A simple clip onto nVent CADDY Cat HP components ensures a secure hold—ultimately enhancing rigidity and stability while minimizing inventory impact and providing flexibility on the job site.

## CERTIFICATIONS




## FEATURES

- Easy beam flange installation
- Works with nVent J-Hook Versa-Mount technology from nVent CADDY

## SPECIFICATIONS

Table 1/1					
Catalog Number	Article Number	Finish	Material	Flange Thickness (FT)	Static Load (F)
CATHPMBC	186078	Electrogalvanized, nVent CADDY Armour	Steel, Spring Steel	16 mm Max	445N

DIAGRAMS

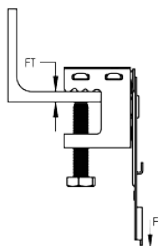

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221  
Option 1 – Customer Care  
Option 2 – Technical Support

Europe

Netherlands:  
+31 800-0200135  
France:  
+33 800 901 793

Europe

Germany:  
800 1890272  
Other Countries:  
+31 13 5835404

APAC

Shanghai:  
+ 86 21 2412 1618/19  
Sydney:  
+61 2 9751 8500



Our powerful portfolio of brands:  
**nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF**  
**TRACER**