


# INC8 INTERNAL STRUT BEAM CLAMP

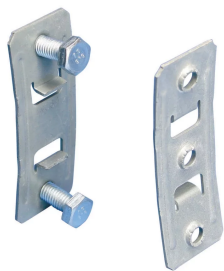

## CERTIFICATIONS



## FEATURES

Mounts strut within beams

## SPECIFICATIONS


Table 1/2						
Catalog Number	Article Number	Material	Finish	Strut Type	A	Screw Diameter (Sc)
INC8	336290	Spring Steel	nVent CADDY Armour	A (41 x 41 mm), C (21 x 41 mm)	13 mm	8

Table 2/2					
Catalog Number	Article Number	Screw Length (L)	Torque (TQ)	Static Load (F)	Packing Quantity
INC8	336290	25mm	6 N·m	450N	1.0000

ADDITIONAL PRODUCT DETAILS

Strut channel must be cut 3/4" (20mm) shorter than the inner distance between the two beam flanges in order to accomodate the clamps.

DIAGRAMS

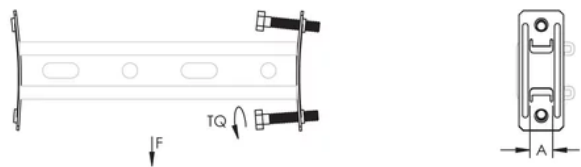

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221  
Option 1 – Customer Care  
Option 2 – Technical Support

Europe

Netherlands:  
+31 800-0200135  
France:  
+33 800 901 793

Europe

Germany:  
800 1890272  
Other Countries:  
+31 13 5835404

APAC

Shanghai:  
+ 86 21 2412 1618/19  
Sydney:  
+61 2 9751 8500



Our powerful portfolio of brands:  
**nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF**  
**TRACER**