


## ATCA FRONT PANEL, ST, REINFORCED, WITH SPRING LOADING

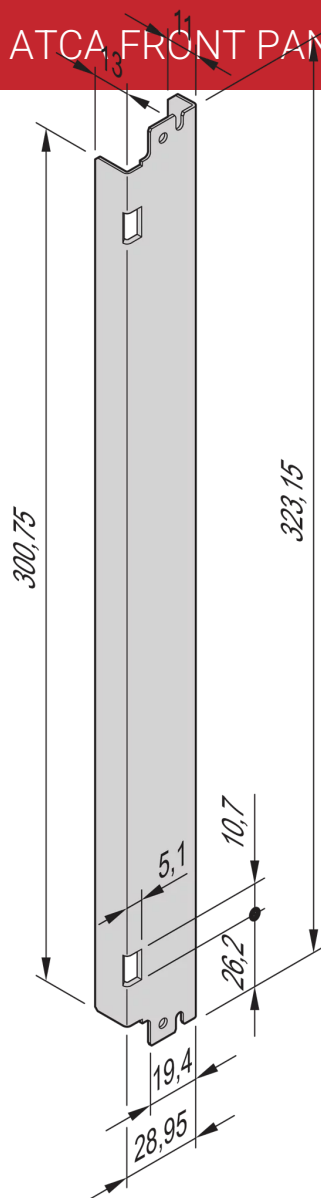

AdvancedTCA front panel for spring-loaded IEA handle with die-cast end piece.

### CERTIFICATIONS

FEATURES

Configuration: Front panel with IEA handle (with/without spring loading)


SPECIFICATIONS

Accessory Type: Front panel

Table 1/2						
Catalog Number	Front Finish	Rear Finish	Material	Rack Height	Rack Width	Width (W)
31596-791	Raw	Raw	Stainless Steel	8U	6HP	29mm
31596-792	Raw	Raw	Stainless Steel	8U	6HP	29mm

Table 2/2			
Catalog Number	Depth (D)	Height (H)	Package Quantity
31596-791	1mm	323.15mm	1
31596-792	1mm	323.15mm	1

DIAGRAMS

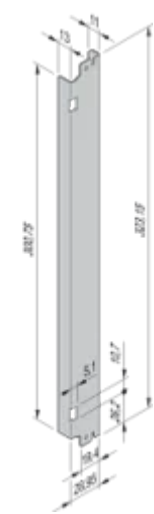

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

#### North America

All locations  
+1.763.422.2661  
Chat with us:  
[schroff.nvent.com](https://schroff.nvent.com)

#### Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[schroff.nvent.com](https://schroff.nvent.com)

#### Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[schroff.nvent.com](https://schroff.nvent.com)

#### Middle East & India

Dubai, United Arab Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[schroff.nvent.com](https://schroff.nvent.com)



Our powerful portfolio of brands:  
**nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF**  
**TRACER**