



NVENT CADDY MACROFIX NI



CERTIFICATIONS



FEATURES

Combo head bolt works with slotted, hex, or Phillips drivers

Includes retaining washer

SPECIFICATIONS

Table 1/3

Catalog Number	Article Number	Material	Finish	Rod Size (RS)	Outer Diameter (OD)	Pipe Size
MXN018S6	595400	Stainless Steel 316 (EN 1.4401)	Electropolished	8	14 - 18 mm	3/8"
MXN026S6	595410	Stainless Steel 316 (EN 1.4401)	Electropolished	8	20 - 26 mm	1/2"
MXN030EG	596230	Steel	Electrogalvanized	8, 10	23 - 30 mm	3/4"
MXN069S6	595475	Stainless Steel 316 (EN 1.4401)	Electropolished	8	62 - 69 mm	


Catalog Number	Article Number	Material	Finish	Rod Size(RS)	Outer Diameter (OD)	Pipe Size
MXN078S6	595490	Stainless Steel 316 (EN 1.4401)	Electropolished	8	69 - 78 mm	2 1/2"
MXN091S6	595500	Stainless Steel 316 (EN 1.4401)	Electropolished	8	85 - 91 mm	3"
MXN098S6	595505	Stainless Steel 316 (EN 1.4401)	Electropolished	10	90 - 98 mm	
MXN116S6	595530	Stainless Steel 316 (EN 1.4401)	Electropolished	10	108 - 116 mm	4"
MXN140S6	595540	Stainless Steel 316 (EN 1.4401)	Electropolished	10	129 - 140 mm	
MXN250EG	596446	Steel	Electrogalvanized	8, 10	240 - 250 mm	
MXN316EG	596448	Steel	Electrogalvanized	8, 10	314 - 316 mm	

Table 2/3						
Catalog Number	Article Number	NB/DN	Width (W)	Thickness (T)	Screw Diameter (Sc)	Screw Length (L)
MXN018S6	595400	10	20 mm	1.5 mm	6	20mm
MXN026S6	595410	15	20 mm	1.5 mm	6	20mm
MXN030EG	596230	20	20 mm	1.5 mm	6	20mm
MXN069S6	595475		20 mm	1.5 mm	6	25mm
MXN078S6	595490	65	25 mm	2 mm	6	25mm
MXN091S6	595500	80	25 mm	2 mm	6	25mm
MXN098S6	595505		25 mm	2 mm	6	25mm
MXN116S6	595530	100	25 mm	2 mm	6	25mm
MXN140S6	595540		25 mm	2.5 mm	6	30mm
MXN250EG	596446		30 mm	3 mm	8	30mm
MXN316EG	596448		30 mm	3 mm	8	30mm

Table 3/3			
Catalog Number	Article Number	Static Load (F)	Certifications
MXN018S6	595400	1000N	
MXN026S6	595410	1000N	
MXN030EG	596230	1000N	
MXN069S6	595475	1000N	
MXN078S6	595490	1000N	

Catalog Number	Article Number	Static Load (F)	Certifications
MXN091S6	595500	1000N	
MXN098S6	595505	1000N	
MXN116S6	595530	1500N	
MXN140S6	595540	1500N	
MXN250EG	596446	2700N	ITB
MXN316EG	596448	2700N	ITB

DIAGRAMS

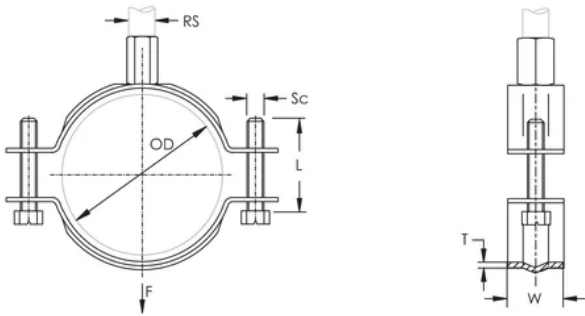

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:
nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF
TRACER