




NVENT CADDY MACROFIX PLUS LF LOW-FRICTION

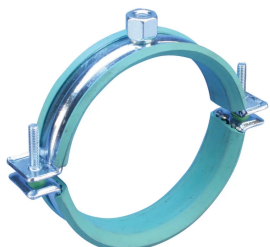

FEATURES

Includes easy closing mechanism

Age resistant lining designed specifically for plastic pipe applications

Low-friction properties allow for expansion, contraction and easy sliding of pipe

Conforms with Manufacturers Standardization Society (MSS) SP-58 (Type 12)

Category II noise reduction according to DIN EN ISO 3822-1

Compliant for sound insulation design according to DIN 4109

SPECIFICATIONS

Finish:	Electrogalvanized
Material:	Steel;EPDM-SBR Rubber
Color:	Green
Temperature:	-50 to 110 °C

Table 1/2

Catalog Number	Article Number	Outer Diameter (OD)	Pipe Size	NB/DN	Plastic Pipe Size	Rod Size (RS)
MPL016	595035	16 mm	3/8"	10		8, 10
MPL020	595036	20 mm	1/2"	15	20mm	8, 10
MPL025	595037	25 mm	3/4"	20	25mm	8, 10
MPL032	595038	32 mm	1"	25	32mm	8, 10
MPL040	595039	40 mm	1 1/4"	32	40mm	8, 10


Catalog Number	Article Number	Outer Diameter (OD)	Pipe Size	NB/DN	Plastic Pipe Size	Rod Size(RS)
MPL050	595040	50 mm	1 1/2"	40	50mm	8, 10
MPL056	595041	56 mm				8, 10
MPL063	595042	63 mm	2"	50	63mm	8, 10
MPL067	595068	67 mm				8, 10
MPL075	595043	75 mm	2 1/2"	65	75mm	8, 10
MPL090	595044	90 mm	3"	80	90mm	8, 10
MPL110	595045	110 mm	4"	100	100mm	8, 10
MPL125	595046	125 mm			110mm	8, 10
MPL140	595047	140 mm	5"	125		8, 10
MPL160	595048	160 mm			160mm	8, 10

Table 2/2				
Catalog Number	Article Number	Width (W)	Thickness (T)	Static Load (F)
MPL016	595035	30 mm	1.5 mm	1125N
MPL020	595036	30 mm	1.5 mm	1125N
MPL025	595037	30 mm	1.5 mm	1125N
MPL032	595038	30 mm	1.5 mm	1125N
MPL040	595039	30 mm	1.5 mm	1125N
MPL050	595040	30 mm	2 mm	1725N
MPL056	595041	30 mm	2 mm	1725N
MPL063	595042	30 mm	2 mm	1725N
MPL067	595068	30 mm	2 mm	1725N
MPL075	595043	30 mm	2 mm	1725N
MPL090	595044	30 mm	2 mm	1725N
MPL110	595045	30 mm	2.5 mm	2000N
MPL125	595046	30 mm	2.5 mm	2000N
MPL140	595047	30 mm	2.5 mm	2000N
MPL160	595048	30 mm	2.5 mm	2000N

ADDITIONAL PRODUCT DETAILS

Lining is EPDM rubber.

DIAGRAMS

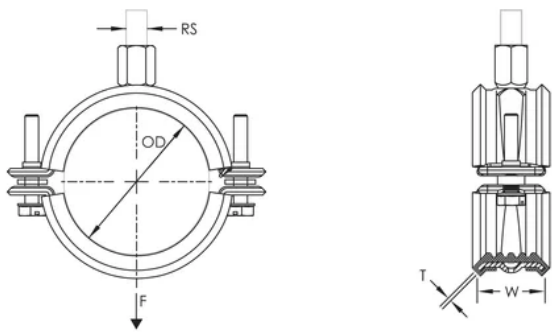

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America
+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical Support

Europe
Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe
Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC
Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:
nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF
TRACER