

## PLUG-IN UNIT KIT WITH TRAPEZOID HANDLE, UNSHIELDED, GREY



Plug-in unit, with static handle and the flat front panel. The grey handle is assembled on the front panel.

### CERTIFICATIONS



### FEATURES

Flat front panel

Handle without extraction function

### SPECIFICATIONS

Table 1/3


| Catalog Number | Type                          | Handle Type       | Mounting       | EMC Shielding | Material | Front Finish |
|----------------|-------------------------------|-------------------|----------------|---------------|----------|--------------|
| 20818-017      | Front Panel with Handle (PIU) | Trapezoid, Static | Screw-on Front | No            | Aluminum | Anodized     |
| 20818-018      | Front Panel with Handle (PIU) | Trapezoid, Static | Screw-on Front | No            | Aluminum | Anodized     |
| 20818-019      | Front Panel with Handle (PIU) | Trapezoid, Static | Screw-on Front | No            | Aluminum | Anodized     |
| 20818-020      | Front Panel with Handle (PIU) | Trapezoid, Static | Screw-on Front | No            | Aluminum | Anodized     |
| 20818-021      | Front Panel with Handle (PIU) | Trapezoid, Static | Screw-on Front | No            | Aluminum | Anodized     |

| Catalog Number | Type                          | Handle Type       | Mounting       | EMC Shielding | Material | Front Finish |
|----------------|-------------------------------|-------------------|----------------|---------------|----------|--------------|
| 20818-022      | Front Panel with Handle (PIU) | Trapezoid, Static | Screw-on Front | No            | Aluminum | Anodized     |
| 20818-023      | Front Panel with Handle (PIU) | Trapezoid, Static | Screw-on Front | No            | Aluminum | Anodized     |
| 20818-024      | Front Panel with Handle (PIU) | Trapezoid, Static | Screw-on Front | No            | Aluminum | Anodized     |
| 20818-025      | Front Panel with Handle (PIU) | Trapezoid, Static | Screw-on Front | No            | Aluminum | Anodized     |
| 20818-026      | Front Panel with Handle (PIU) | Trapezoid, Static | Screw-on Front | No            | Aluminum | Anodized     |
| 20818-027      | Front Panel with Handle (PIU) | Trapezoid, Static | Screw-on Front | No            | Aluminum | Anodized     |
| 20818-028      | Front Panel with Handle (PIU) | Trapezoid, Static | Screw-on Front | No            | Aluminum | Anodized     |
| 20818-029      | Front Panel with Handle (PIU) | Trapezoid, Static | Screw-on Front | No            | Aluminum | Anodized     |
| 20818-120      | Front Panel with Handle (PIU) | Trapezoid, Static | Screw-on Front | No            | Aluminum | Anodized     |
| 20818-162      | Front Panel with Handle (PIU) | Trapezoid, Static | Screw-on Front | No            | Aluminum | Anodized     |

| Table 2/3      |             |               |             |            |            |           |
|----------------|-------------|---------------|-------------|------------|------------|-----------|
| Catalog Number | Rear Finish | Treated Edges | Rack Height | Height (H) | Rack Width | Width (W) |
| 20818-017      | Passivated  | No            | 3U          | 128.4mm    | 3HP        | 14.9mm    |
| 20818-018      | Passivated  | No            | 3U          | 128.4mm    | 4HP        | 20mm      |
| 20818-019      | Passivated  | No            | 3U          | 128.4mm    | 5HP        | 25mm      |
| 20818-020      | Passivated  | No            | 3U          | 128.4mm    | 6HP        | 30.1mm    |
| 20818-021      | Passivated  | No            | 3U          | 128.4mm    | 7HP        | 35.2mm    |
| 20818-022      | Passivated  | No            | 3U          | 128.4mm    | 8HP        | 40.3mm    |
| 20818-023      | Passivated  | No            | 3U          | 128.4mm    | 10HP       | 50.5mm    |
| 20818-024      | Passivated  | No            | 3U          | 128.4mm    | 12HP       | 60.6mm    |
| 20818-025      | Passivated  | No            | 6U          | 261.8mm    | 4HP        | 20mm      |
| 20818-026      | Passivated  | No            | 6U          | 261.8mm    | 5HP        | 25mm      |
| 20818-027      | Passivated  | No            | 6U          | 261.8mm    | 6HP        | 30.1mm    |
| 20818-028      | Passivated  | No            | 6U          | 261.8mm    | 8HP        | 40.3mm    |
| 20818-029      | Passivated  | No            | 6U          | 261.8mm    | 10HP       | 50.5mm    |
| 20818-120      | Passivated  | No            | 6U          | 261.8mm    | 12HP       | 60.6mm    |

| Catalog Number | Rear Finish | Treated Edges | Rack Height | Height (H) | Rack Width | Width (W) |
|----------------|-------------|---------------|-------------|------------|------------|-----------|
| 20818-162      | Passivated  | No            | 6U          | 261.8mm    | 7HP        | 35.2mm    |

| Table 3/3      |                                           |                     |                  |                      |
|----------------|-------------------------------------------|---------------------|------------------|----------------------|
| Catalog Number | Complies With                             | Flammability Rating | Package Quantity | Finish               |
| 20818-017      | EN 45545-2, R22-R24, HL3, IEC 60297-3-101 | UL® 94V-0           | 1                | Anodized, Passivated |
| 20818-018      | EN 45545-2, R22-R24, HL3, IEC 60297-3-101 | UL® 94V-0           | 1                | Anodized, Passivated |
| 20818-019      | EN 45545-2, R22-R24, HL3, IEC 60297-3-101 | UL® 94V-0           | 1                | Anodized, Passivated |
| 20818-020      | EN 45545-2, R22-R24, HL3, IEC 60297-3-101 | UL® 94V-0           | 1                | Anodized, Passivated |
| 20818-021      | EN 45545-2, R22-R24, HL3, IEC 60297-3-101 | UL® 94V-0           | 1                | Anodized, Passivated |
| 20818-022      | EN 45545-2, R22-R24, HL3, IEC 60297-3-101 | UL® 94V-0           | 1                | Anodized, Passivated |
| 20818-023      | EN 45545-2, R22-R24, HL3, IEC 60297-3-101 | UL® 94V-0           | 1                | Anodized, Passivated |
| 20818-024      | EN 45545-2, R22-R24, HL3, IEC 60297-3-101 | UL® 94V-0           | 1                | Anodized, Passivated |
| 20818-025      | EN 45545-2, R22-R24, HL3, IEC 60297-3-101 | UL® 94V-0           | 1                | Anodized, Passivated |
| 20818-026      | EN 45545-2, R22-R24, HL3, IEC 60297-3-101 | UL® 94V-0           | 1                | Anodized, Passivated |
| 20818-027      | EN 45545-2, R22-R24, HL3, IEC 60297-3-101 | UL® 94V-0           | 1                | Anodized, Passivated |
| 20818-028      | EN 45545-2, R22-R24, HL3, IEC 60297-3-101 | UL® 94V-0           | 1                | Anodized, Passivated |
| 20818-029      | EN 45545-2, R22-R24, HL3, IEC 60297-3-101 | UL® 94V-0           | 1                | Anodized, Passivated |
| 20818-120      | EN 45545-2, R22-R24, HL3, IEC 60297-3-101 | UL® 94V-0           | 1                | Anodized, Passivated |
| 20818-162      | EN 45545-2, R22-R24, HL3, IEC 60297-3-101 | UL® 94V-0           | 1                | Anodized, Passivated |

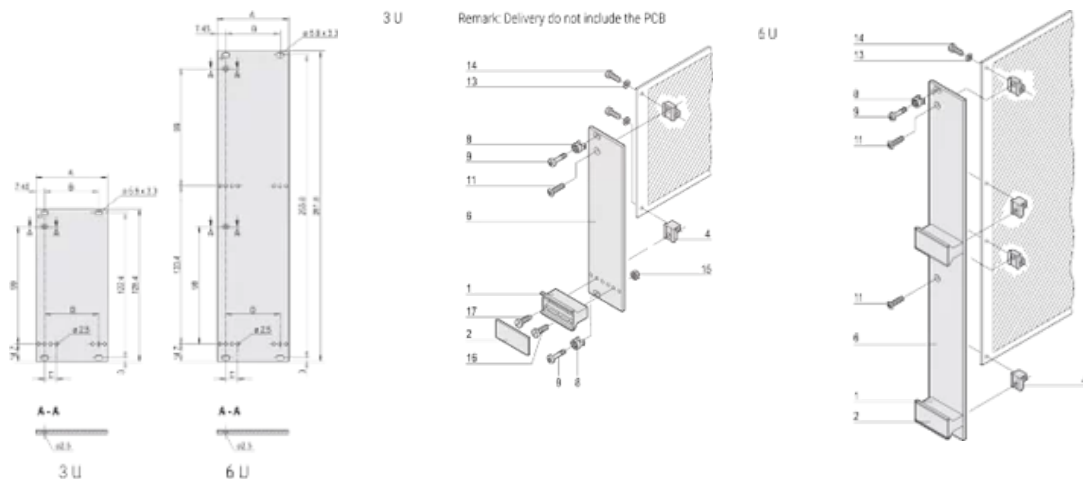

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

### North America

All locations  
+1.763.422.2661  
Chat with us:  
[schroff.nvent.com](http://schroff.nvent.com)

### Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[schroff.nvent.com](http://schroff.nvent.com)

### Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[schroff.nvent.com](http://schroff.nvent.com)

### Middle East & India

Dubai, United Arab Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[schroff.nvent.com](http://schroff.nvent.com)



Our powerful portfolio of brands:  
**nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF**  
**TRACER**