


## PROLINE CONTAINMENT SYSTEM WINDOW CEILING PANEL

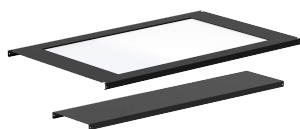

Window Ceiling Panels have easily modified, .22-inch (6 mm) polycarbonate panels to accommodate local fire-suppression codes. Overhead window panel made of .22-in. polycarbonate.

### FEATURES

Frame made of 16 gauge steel

Overhead window panel made of .22-inch polycarbonate

Sealed containment, Window Ceiling Panels have easily modified .22-in. polycarbonate panels to accommodate local firesuppression codes (sprinkler heads)

Tool-less Ceiling Panels are easy to install and remove for cleaning and provide above-the-cabinet access to cables, equipment and systems

Clear, transparent door and roof panels provide maximum light to aisleway

### SPECIFICATIONS

Table 1/3

Catalog Number	Article Number	Product Family	Height	Use With Cabinet Width	Aisle Width	Color Code
PCP312	38766	ProLine Containment System	143mm	300 mmmm	1219mm	RAL 9005

Table 2/3

Catalog Number	Article Number	Width	Depth	Color	Material	Finish
PCP312	38766	1309mm	297mm	Jet Black	Mild Steel	Powder Coated

Table 3/3

Catalog Number	Article Number	Thickness
----------------	----------------	-----------

**WARNING**

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:  
**nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF**  
**TRACER**