



## DOSR DOUBLE OFFSET SURGE RESTRAINT FOR CPVC PIPE



### CERTIFICATIONS



### FEATURES

Provides quick and easy snap-in installation of pipe

Built-in nail tab allows for fast, temporary mounting to any surface

Rated for use with CPVC fire sprinkler pipe

Positions pipe 1-1/2" (38 mm) out and up from the mounting surface eliminating the need for wooden spacer blocks

Meets the UL® 203 stringent upward thrust requirement

UL® Listed as both a hanger and restraint in the double offset orientation

Complies with static load requirements of NFPA® 13

Includes mounting screws

Can be used with 3TW backing nut on composite wood joist installations

### SPECIFICATIONS

**Finish:** Pregalvanized

**Material:** Steel


Table 1/2

Catalog Number	Pipe Size	Hole Size (HS)	Height (H)	Width (W)	Depth (D)	A
DOSR075	3/4"	5.1 mm	132.1 mm	25.4 mm	88.9mm	38.1 mm
DOSR100	1"	5.1 mm	147.3 mm	25.4 mm	86.4mm	38.1 mm

Table 2/2

Catalog Number	Thickness (T)	Hanger Spacing
DOSR075	1.3 mm	1.65 m Max
DOSR100	1.3 mm	1.65 m Max

## DIAGRAMS

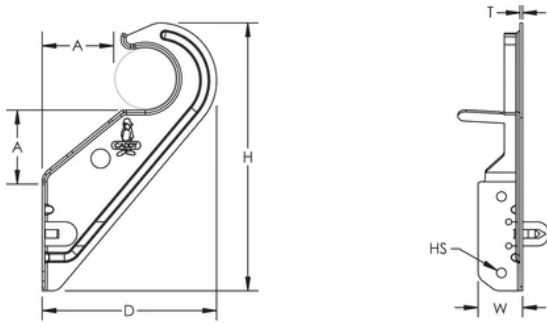

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

### North America

+1.800.753.9221  
Option 1 – Customer Care  
Option 2 – Technical Support

### Europe

Netherlands:  
+31 800-0200135  
France:  
+33 800 901 793

### Europe

Germany:  
800 1890272  
Other Countries:  
+31 13 5835404

### APAC

Shanghai:  
+ 86 21 2412 1618/19  
Sydney:  
+61 2 9751 8500



Our powerful portfolio of brands:  
nVent.com **CADDY ERICO HOFFMAN RAYCHEM SCHROFF**  
**TRACER**