


## CABLETEK HORIZONTAL CABLE MANAGER 2U DOUBLE SIDED, FITS 19IN, BLACK, COMPOSITE

### CATALOG NUMBER

**DCHD2**

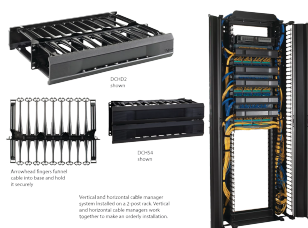

The CableTek Horizontal Cable Manager features heavy-duty endposts, arrowhead fingers and tool-less mounting to easily route Cat 5e, 6 and 6A cable horizontally in standard 19-in. cabinets or on 2- or 4-post open frame racks.

### INDUSTRY STANDARDS

EIA 310-D

### FEATURES

Snap-in mounting provision holds cable manager in place while mounting screws are installed

Robust arrowhead fingers are shaped to funnel cables into base and are made of black composite material

Robust rounded end posts support cable as it enters and leaves cable manager and maintains proper cable bend radius

Deep cable compartments allow maximum cable density

Rounded edges throughout protect cable jackets from damage

Pass-through holes on double-sided models protect cable while facilitating routing between front and back sides

Single- and double-sided units provide high cable capacity, including 5e, 6 and 6A cables

1 RU and 2 RU heights allow greater flexibility in optimizing rack capacity

Removable hinged cover opens top or bottom, snaps closed for assured cable protection and professional appearance

Double-sided model has covers on both front and back

Covers stay open during installation and maintenance procedures

Horizontal and vertical cable managers designed as a system for streamlined appearance and improved functionality

Combination head 10-32 and 12-24 screws included for mounting

Made of UL listed black composite material

### PRODUCT ATTRIBUTES

Article Number: 17243

Material: ABS

Finish: Smooth Matte

Color: Jet Black

Color Code: RAL 9005

Fill Rate, Back Cable, Cat 5e 0.22 in: 223

Fill Rate, Back Cable, Cat 6 0.25 in: 172

Fill Rate, Back Cable, Cat 6A 0.30 in: 119

Rack Units: 2U

Fill Rate, Front Cable, Cat 5e 0.22 in: 208

Fill Rate, Front Cable, Cat 6 0.25 in: 161

Fill Rate, Front Cable, Cat 6A 0.30 in: 112

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:  
**nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF**  
**TRACER**