



FCS HEIGHT ADJUSTABLE LOOP HANGER



CERTIFICATIONS



FEATURES

Recommended for the suspension of stationary non-insulated fire sprinkler pipe

Redesigned strap and cup nut minimize friction for easier adjustment up and down the threaded rod (1/2" to 4" sizes)

Formed tips on the upper strap simplify disassembly and reassembly of the hanger

Rolled edges on the strap help to guide the pipe through, limiting binding and damage to metal or plastic pipe

Package includes all necessary hardware for installation

SPECIFICATIONS

Finish: Electrogalvanized

Material: Steel

Table 1/3

Catalog Number	Article Number	Pipe Size	Pipe Size Range	NB/DN	Outer Diameter (OD)	Rod Size (RS)
FCS0075M10	597968	3/4"	0.75 in	20	27 mm	10
FCS0100M10	597969	1"	1 in	25	34 mm	10


Catalog Number	Article Number	Pipe Size	Pipe Size Range	NB/DN	Outer Diameter (OD)	Rod Size(RS)
FCS0100M8	597963	1"	1 in	25	34 mm	8
FCS0125M10	597971	1 1/4"	1.25 in min	32	43 mm	10
FCS0125M8	597964	1 1/4"	1.25 in min	32	43 mm	8
FCS0150M10	597972	1 1/2"	1.5 in	40	48 mm	10
FCS0150M8	597965	1 1/2"	1.5 in	40	48 mm	8
FCS0200M10	597973	2"	2 in min	50	60 mm	10
FCS0200M8	597966	2"	2 in min	50	60 mm	8
FCS0250M10	597974	2 1/2"	2.5 in	65	76 mm	10
FCS0300M10	597975	3"	3 in	80	89 mm	10
FCS0400M10	597976	4"	4 in	100	114 mm	10
FCS0500M12	597977	5"	5 in	125	140 mm	12
FCS0600M12	597978	6"	6 in	150	165 mm	12
FCS0800M16	597979	8"	8 in	200	219 mm	16
FCS1000M20	597981	10"	10 in	250	273 mm	20

Table 2/3						
Catalog Number	Article Number	Width (W)	A	B	C	Wrench Size
FCS0075M10	597968	10 mm	76 mm	31 mm	17 mm	15 mm
FCS0100M10	597969	10 mm	87 mm	36 mm	19 mm	15 mm
FCS0100M8	597963	10 mm	85 mm	36 mm	19 mm	13 mm
FCS0125M10	597971	10 mm	91 mm	36 mm	15 mm	15 mm
FCS0125M8	597964	10 mm	89 mm	36 mm	15 mm	13 mm
FCS0150M10	597972	10 mm	99 mm	41 mm	17 mm	15 mm
FCS0150M8	597965	10 mm	97 mm	41 mm	17 mm	13 mm
FCS0200M10	597973	10 mm	114 mm	50 mm	20 mm	15 mm
FCS0200M8	597966	10 mm	112 mm	50 mm	20 mm	13 mm
FCS0250M10	597974	10 mm	142 mm	68 mm	30 mm	15 mm
FCS0300M10	597975	10 mm	164 mm	83 mm	39 mm	15 mm
FCS0400M10	597976	10 mm	206 mm	112 mm	55 mm	15 mm
FCS0500M12	597977	15 mm	227 mm	114 mm	44 mm	18 mm
FCS0600M12	597978	15 mm	272 mm	146 mm	63 mm	18 mm
FCS0800M16	597979	25 mm	349 mm	184 mm	75 mm	24 mm
FCS1000M20	597981	25 mm	480 mm	279 mm	143 mm	30 mm

Table 3/3

Catalog Number	Article Number	Certifications
FCS0075M10	597968	FM Approved, Pipe Hanger Components, VdS G4050054
FCS0100M10	597969	FM Approved, Pipe Hanger Components, VdS G4050054
FCS0100M8	597963	VdS G4050054
FCS0125M10	597971	FM Approved, Pipe Hanger Components, VdS G4050054
FCS0125M8	597964	VdS G4050054
FCS0150M10	597972	FM Approved, Pipe Hanger Components, VdS G4050054
FCS0150M8	597965	VdS G4050054
FCS0200M10	597973	FM Approved, Pipe Hanger Components, VdS G4050054
FCS0200M8	597966	VdS G4050054
FCS0250M10	597974	FM Approved, Pipe Hanger Components, VdS G4050054
FCS0300M10	597975	FM Approved, Pipe Hanger Components, VdS G4050054
FCS0400M10	597976	FM Approved, Pipe Hanger Components, VdS G4050054
FCS0500M12	597977	FM Approved, Pipe Hanger Components, VdS G4050054
FCS0600M12	597978	FM Approved, Pipe Hanger Components, VdS G4050054
FCS0800M16	597979	FM Approved, Pipe Hanger Components, VdS G4050054
FCS1000M20	597981	VdS G4050054

DIAGRAMS

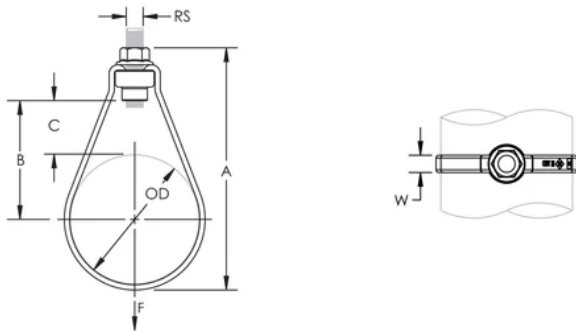

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:
nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF
TRACER