


## FRONT PANEL, UNSHIELDED, BOTTOM HINGED

Unshielded front panel bottom hinged.

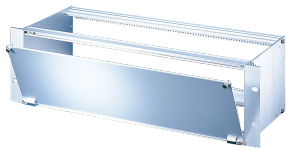

### CERTIFICATIONS



### FEATURES

Front panel can be unhinged at 135° (not RatiopacPRO) opening angle

Enables mounting on horizontal rails

### SPECIFICATIONS

Table 1/3

| Catalog Number | Treated Edges | Front Finish | Rear Finish | EMC Shielding | Rack Width | Package Quantity |
|----------------|---------------|--------------|-------------|---------------|------------|------------------|
| 20838-271      | No            | Anodized     | Conductive  | No            | 42 HP      | 1                |
| 20838-272      | No            | Anodized     | Conductive  | No            | 63 HP      | 1                |
| 20838-273      | No            | Anodized     | Conductive  | No            | 84 HP      | 1                |
| 20838-274      | No            | Anodized     | Conductive  | No            | 42 HP      | 1                |
| 20838-275      | No            | Anodized     | Conductive  | No            | 63 HP      | 1                |
| 20838-276      | No            | Anodized     | Conductive  | No            | 84 HP      | 1                |
| 20838-277      | No            | Anodized     | Conductive  | No            | 42 HP      | 1                |
| 20838-278      | No            | Anodized     | Conductive  | No            | 63 HP      | 1                |

| Catalog Number | Treated Edges | Front Finish | Rear Finish | EMC Shielding | Rack Width | Package Quantity |
|----------------|---------------|--------------|-------------|---------------|------------|------------------|
| 20838-279      | No            | Anodized     | Conductive  | No            | 84 HP      | 1                |
| 20838-280      | No            | Anodized     | Conductive  | No            | 28 HP      | 1                |

| Table 2/3      |          |              |                            |             |          |                                 |
|----------------|----------|--------------|----------------------------|-------------|----------|---------------------------------|
| Catalog Number | Height   | Product Type | Type                       | Rack Height | Width    | Complies With                   |
| 20838-271      | 128.4 mm | Front Panel  | Front Panel without Handle | 3 U         | 213 mm   | IEC 60297-3-101, IEEE 1101.1/10 |
| 20838-272      | 128.4 mm | Front Panel  | Front Panel without Handle | 3 U         | 319.7 mm | IEC 60297-3-101, IEEE 1101.1/10 |
| 20838-273      | 128.4 mm | Front Panel  | Front Panel without Handle | 3 U         | 426.4 mm | IEC 60297-3-101, IEEE 1101.1/10 |
| 20838-274      | 261.8 mm | Front Panel  | Front Panel without Handle | 6 U         | 213 mm   | IEC 60297-3-101, IEEE 1101.1/10 |
| 20838-275      | 261.8 mm | Front Panel  | Front Panel without Handle | 6 U         | 319.7 mm | IEC 60297-3-101, IEEE 1101.1/10 |
| 20838-276      | 261.8 mm | Front Panel  | Front Panel without Handle | 6 U         | 426.4 mm | IEC 60297-3-101, IEEE 1101.1/10 |
| 20838-277      | 172.9 mm | Front Panel  | Front Panel without Handle | 4 U         | 213 mm   | IEC 60297-3-101, IEEE 1101.1/10 |
| 20838-278      | 172.9 mm | Front Panel  | Front Panel without Handle | 4 U         | 319.7 mm | IEC 60297-3-101, IEEE 1101.1/10 |
| 20838-279      | 172.9 mm | Front Panel  | Front Panel without Handle | 4 U         | 426.4 mm | IEC 60297-3-101, IEEE 1101.1/10 |
| 20838-280      | 128.4 mm | Front Panel  | Front Panel without Handle | 3 U         | 141.9 mm | IEC 60297-3-101, IEEE 1101.1/10 |

| Table 3/3      |                |          |
|----------------|----------------|----------|
| Catalog Number | Mounting       | Material |
| 20838-271      | Hinged, Bottom | Aluminum |
| 20838-272      | Hinged, Bottom | Aluminum |
| 20838-273      | Hinged, Bottom | Aluminum |

| Catalog Number | Mounting       | Material |
|----------------|----------------|----------|
| 20838-274      | Hinged, Bottom | Aluminum |
| 20838-275      | Hinged, Bottom | Aluminum |
| 20838-276      | Hinged, Bottom | Aluminum |
| 20838-277      | Hinged, Bottom | Aluminum |
| 20838-278      | Hinged, Bottom | Aluminum |
| 20838-279      | Hinged, Bottom | Aluminum |
| 20838-280      | Hinged, Bottom | Aluminum |

## ADDITIONAL PRODUCT DETAILS

Front panel can be removed in opened position (> 135°).

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:  
**nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF**  
**TRACER**