



## BRANCH LINE RESTRAINT STRUCTURE ATTACHMENT TO WOOD/CONCRETE



### CERTIFICATIONS



### FEATURES

Swivel barrel nut accepts 3/8" or 1/2" (M10 or M12) threaded rod

Attaches to wood or concrete where cracked concrete approval is not needed

### SPECIFICATIONS

**Finish:** Electrogalvanized

**Material:** Steel

Table 1/2

Catalog Number	Article Number	Rod Size (RS)	Height (H)	Length (L)	Width (W)	Screw Diameter (Sc)
CSBBRS2EG		3/8, 1/2	28.2 mm	40.4 mm	26.9 mm	1/4"
CSBBRS2MEG	402240	10, 12	28.2 mm	40.4 mm	26.9 mm	1/4"

Table 2/2


Catalog Number	Article Number	Screw Length (L)	Drill Bit Diameter
CSBBRS2EG		44.5mm	5mm

Catalog Number	Article Number	Screw Length (L)	Drill Bit Diameter
CSBBRS2MEG	402240	44.5mm	5mm

### ADDITIONAL PRODUCT DETAILS

Branch line structural attachments are for restraint only and not for the hanging of fire sprinkler piping.

### DIAGRAMS

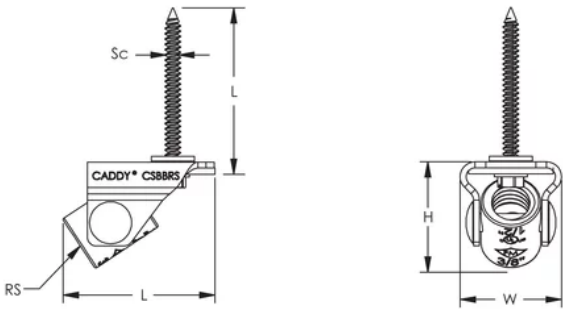

### WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

**North America**  
+1.800.753.9221  
Option 1 – Customer Care  
Option 2 – Technical Support

**Europe**  
Netherlands:  
+31 800-0200135  
France:  
+33 800 901 793

**Europe**  
Germany:  
800 1890272  
Other Countries:  
+31 13 5835404

**APAC**  
Shanghai:  
+ 86 21 2412 1618/19  
Sydney:  
+61 2 9751 8500