



NVENT CADDY SPEED LINK SLK WITH THREADED STUD END



CERTIFICATIONS



FEATURES

- Complete system includes wire, locking device and pre-assembled threaded stud end fitting
- Attaches to structures with threaded anchors or devices with threaded hole
- Connects directly to threaded devices in trapeze assemblies, light fixtures, HVAC assemblies or signage

SPECIFICATIONS

Static Load Safety Factor:	5:1
Finish:	Electrogalvanized
Material:	Steel;Polypropylene;Zinc Alloy
Complies With:	SMACNA HVAC-DCS


Table 1/2						
Catalog Number	Wire Rope Diameter	Wire Rope Length	Rod Size (RS)	Screw Length (L)	Height (H)	Width (W)
SLK15L2SE250	1.5 mm	2m	1/4	25mm	55 mm	19 mm
SLK15L3SE250	1.5 mm	3m	1/4	25mm	55 mm	19 mm
SLK15L5SE250	1.5 mm	5m	1/4	25mm	55 mm	19 mm

Catalog Number	Wire Rope Diameter	Wire Rope Length	Rod Size(RS)	ScrewLength (L)	Height (H)	Width (W)
SLK2L2SE250	2 mm	2m	1/4	25mm	55 mm	19 mm
SLK2L5SE250	2 mm	5m	1/4	25mm	55 mm	19 mm
SLK3L1SE375	3 mm	1m	3/8	45mm	62 mm	24 mm
SLK3L2SE375	3 mm	2m	3/8	45mm	62 mm	24 mm
SLK3L3SE375	3 mm	3m	3/8	45mm	62 mm	24 mm
SLK3L7SE375	3 mm	7m	3/8	45mm	62 mm	24 mm

Table 2/2

Catalog Number	Thickness (T)	Angle (a)	Static Load (F)	Certifications
SLK15L2SE250	12.5 mm	90 ° Max	195N	cUL, UL
SLK15L3SE250	12.5 mm	90 ° Max	195N	cUL, UL
SLK15L5SE250	12.5 mm	90 ° Max	195N	cUL, UL
SLK2L2SE250	12.5 mm	90 ° Max	440N	cUL, UL
SLK2L5SE250	12.5 mm	90 ° Max	440N	cUL, UL
SLK3L1SE375	16 mm	90 ° Max	890N	
SLK3L2SE375	16 mm	90 ° Max	890N	
SLK3L3SE375	16 mm	90 ° Max	890N	
SLK3L7SE375	16 mm	90 ° Max	890N	

DIAGRAMS

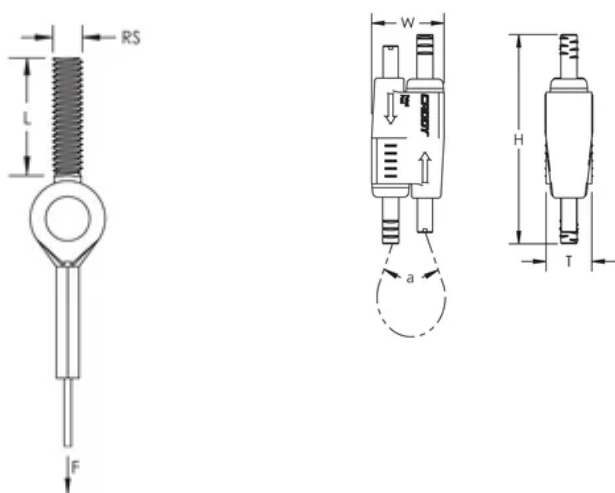

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:
nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF
TRACER