




NVENT CADDY CUSHION CLAMP INSULATED STRUT CLAMP FOR PIPE/TUBE

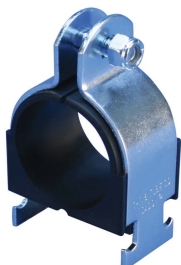

FEATURES

Fits into open side of strut channel

Plastic cushion is hinged to spread apart for easy installation

Reduces noise and absorbs shock by gripping the pipe/tube firmly

Square neck of carriage bolt prevents over-tightening

Nylon locknut prevents loosening under vibration

FM® Specification Tested (from 3/8" to 4" of Copper Tube Size)

SPECIFICATIONS

Material: Steel;Polypropylene

Finish: Zinc Chromate

Table 1/2


Catalog Number	Article Number	Outer Diameter (OD)	Copper Tube Size	Pipe Size	NB/DN	Width (W)
CCC0025	598882	6.3 mm				39.7 mm
CCC0037	598883	9.5 mm	1/4"			39.7 mm
CCC0050	598884	12.7 mm	3/8"	1/4"	8	39.7 mm
CCC0062	598886	15.8 mm	1/2"	3/8"	10	39.7 mm
CCC0087	598891	22.2 mm	3/4"	1/2"	15	39.7 mm
CCC0075	598888	19.1 mm	5/8"			39.7 mm

Catalog Number	Article Number	Outer Diameter (OD)	Copper Tube Size	Pipe Size	NB/DN	Width (W)
CCC0100	598892	25.4 mm		3/4"	20	39.7 mm
CCC0112	598894	28.6 mm	1"			39.7 mm
CCC0125	598895	31.8 mm		1"	25	39.7 mm
CCC0137	598897	34.9 mm	1 1/4"			39.7 mm
CCC0162	598899	41.3 mm	1 1/2"	1 1/4"	32	39.7 mm
CCC0150	598898	38.1 mm				39.7 mm
CCC0187	598903	47.6 mm		1 1/2"	40	39.7 mm
CCC0212	598906	53.9 mm	2"			39.7 mm
CCC0237	598908	60.3 mm		2"	50	39.7 mm
CCC0262	598941	66.7 mm	2 1/2"			39.7 mm
CCC0312	598945	79.4 mm	3"			39.7 mm
CCC0412	598953	104.8 mm	4"			39.7 mm
CCC0450	598957	114.3 mm		4"	100	39.7 mm

Table 2/2			
Catalog Number	Article Number	A	B
CCC0025	598882	15.7 mm	32.2 mm
CCC0037	598883	18.9 mm	35.4 mm
CCC0050	598884	22.1 mm	38.6 mm
CCC0062	598886	25.2 mm	41.7 mm
CCC0087	598891	31.6 mm	48.1 mm
CCC0075	598888	28.4 mm	44.9 mm
CCC0100	598892	34.8 mm	51.3 mm
CCC0112	598894	39 mm	62.4 mm
CCC0125	598895	42.1 mm	65.6 mm
CCC0137	598897	45.3 mm	68.8 mm
CCC0162	598899	51.6 mm	75.1 mm
CCC0150	598898	48.5 mm	72 mm
CCC0187	598903	59 mm	81.5 mm
CCC0212	598906	68.5 mm	91 mm
CCC0237	598908	74.9 mm	97.4 mm
CCC0262	598941	81.2 mm	103.7 mm
CCC0312	598945	93.9 mm	116.4 mm
CCC0412	598953	122.5 mm	151 mm

Catalog Number	Article Number	A	B
CCC0450	598957	132 mm	160.5 mm

DIAGRAMS

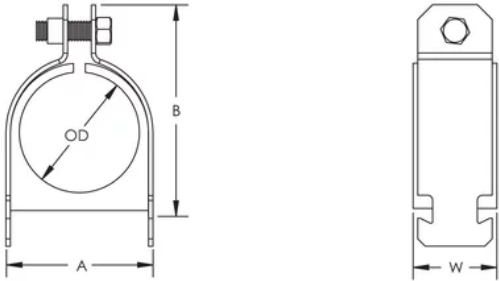

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America
+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical Support

Europe
Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe
Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC
Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500