

## MULTI-FUNCTION C-CLAMP



### FEATURES

Multi-functional beam clamp

Use with Cable/Conduit/Pipe Clamp or Square Washer for Multi-Function C-Clamp

### SPECIFICATIONS

**Finish:** Hot-Dip Galvanized

Table 1/2

Catalog Number	Article Number	Material	Flange Thickness (FT)	Hole Size (HS)	Screw Diameter (Sc)	Screw Length (L)
C20HD	336100	Steel	4 - 20 mm	14 mm	6	25mm
C20S4	336130	Stainless Steel 304 (EN 1.4301)	4 - 20 mm	14 mm	6	25mm
C30HD	336110	Steel	17 - 30 mm	14 mm	8	30mm
C30S4	336140	Stainless Steel 304 (EN 1.4301)	17 - 30 mm	14 mm	8	30mm
C45HD	336120	Steel	30 - 44 mm	14 mm	8	30mm
C45S4	336150	Stainless Steel 304 (EN 1.4301)	30 - 44 mm	14 mm	8	30mm

Table 2/2


Catalog Number	Article Number	Torque (TQ)	Static Load (F)
C20HD	336100	3 N·m	1100N

Catalog Number	Article Number	Torque (TQ)	Static Load (F)
C20S4	336130	3 N·m	1100N
C30HD	336110	3 N·m	1100N
C30S4	336140	3 N·m	1100N
C45HD	336120	3 N·m	1100N
C45S4	336150	3 N·m	1100N

### ADDITIONAL PRODUCT DETAILS

Setscrew must be tightened and torqued onto the sloped side of the I-beam.

### DIAGRAMS

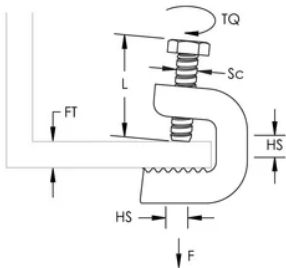

### WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

<b>North America</b> +1.800.753.9221 Option 1 – Customer Care Option 2 – Technical Support	<b>Europe</b> Netherlands: +31 800-0200135 France: +33 800 901 793	<b>Europe</b> Germany: 800 1890272 Other Countries: +31 13 5835404	<b>APAC</b> Shanghai: + 86 21 2412 1618/19 Sydney: +61 2 9751 8500
-----------------------------------------------------------------------------------------------------	--------------------------------------------------------------------------------	--------------------------------------------------------------------------------	--------------------------------------------------------------------------------