

# ECN NUT FOR C-CHANNEL E5



## FEATURES

Channel nut for C-Profiles

## SPECIFICATIONS

**Finish:** Hot-Dip Galvanized

Table 1/1


Catalog Number	Article Number	Material	Rod Size (RS)	Thickness (T)	A	B
E5CN6HD	335170	Steel	6	5 mm	22 mm	13 mm
E5CN6S4	335200	Stainless Steel 304 (EN 1.4301)	6	5 mm	22 mm	13 mm
E5CN10HD	335190	Steel	10	6 mm	22 mm	13 mm
E5CN8HD	335180	Steel	8	6 mm	22 mm	13 mm

## ADDITIONAL PRODUCT DETAILS

Sliding force F2 is limited to 600 N for all types of Nuts and T-Bolts for C-channel System.

Nuts and T-Bolts for C-channel System	
C-Channel Type	Pullout Force F1
E5	2600 N

DIAGRAMS

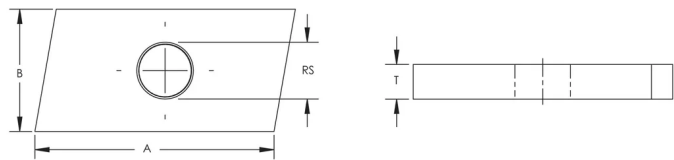

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221  
Option 1 – Customer Care  
Option 2 – Technical Support

Europe

Netherlands:  
+31 800-0200135  
France:  
+33 800 901 793

Europe

Germany:  
800 1890272  
Other Countries:  
+31 13 5835404

APAC

Shanghai:  
+ 86 21 2412 1618/19  
Sydney:  
+61 2 9751 8500



Our powerful portfolio of brands:  
**nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF**  
**TRACER**