

PLUG-IN UNIT KIT WITH TRAPEZOID HANDLE, UNSHIELDED, GREY



Plug-in unit, with static handle and the flat front panel. The grey handle is assembled on the front panel.

CERTIFICATIONS



FEATURES

Flat front panel

Handle without extraction function

SPECIFICATIONS

Table 1/3


Catalog Number	Type	Handle Type	Mounting	EMC Shielding	Material	Front Finish
20818-017	Front Panel with Handle (PIU)	Trapezoid, Static	Screw-on Front	No	Aluminum	Anodized
20818-018	Front Panel with Handle (PIU)	Trapezoid, Static	Screw-on Front	No	Aluminum	Anodized
20818-019	Front Panel with Handle (PIU)	Trapezoid, Static	Screw-on Front	No	Aluminum	Anodized
20818-020	Front Panel with Handle (PIU)	Trapezoid, Static	Screw-on Front	No	Aluminum	Anodized
20818-021	Front Panel with Handle (PIU)	Trapezoid, Static	Screw-on Front	No	Aluminum	Anodized

Catalog Number	Type	Handle Type	Mounting	EMC Shielding	Material	Front Finish
20818-022	Front Panel with Handle (PIU)	Trapezoid, Static	Screw-on Front	No	Aluminum	Anodized
20818-023	Front Panel with Handle (PIU)	Trapezoid, Static	Screw-on Front	No	Aluminum	Anodized
20818-024	Front Panel with Handle (PIU)	Trapezoid, Static	Screw-on Front	No	Aluminum	Anodized
20818-025	Front Panel with Handle (PIU)	Trapezoid, Static	Screw-on Front	No	Aluminum	Anodized
20818-026	Front Panel with Handle (PIU)	Trapezoid, Static	Screw-on Front	No	Aluminum	Anodized
20818-027	Front Panel with Handle (PIU)	Trapezoid, Static	Screw-on Front	No	Aluminum	Anodized
20818-028	Front Panel with Handle (PIU)	Trapezoid, Static	Screw-on Front	No	Aluminum	Anodized
20818-029	Front Panel with Handle (PIU)	Trapezoid, Static	Screw-on Front	No	Aluminum	Anodized
20818-120	Front Panel with Handle (PIU)	Trapezoid, Static	Screw-on Front	No	Aluminum	Anodized
20818-162	Front Panel with Handle (PIU)	Trapezoid, Static	Screw-on Front	No	Aluminum	Anodized

Table 2/3						
Catalog Number	Rear Finish	Treated Edges	Rack Height	Height (H)	Rack Width	Width (W)
20818-017	Passivated	No	3U	128.4mm	3HP	14.9mm
20818-018	Passivated	No	3U	128.4mm	4HP	20mm
20818-019	Passivated	No	3U	128.4mm	5HP	25mm
20818-020	Passivated	No	3U	128.4mm	6HP	30.1mm
20818-021	Passivated	No	3U	128.4mm	7HP	35.2mm
20818-022	Passivated	No	3U	128.4mm	8HP	40.3mm
20818-023	Passivated	No	3U	128.4mm	10HP	50.5mm
20818-024	Passivated	No	3U	128.4mm	12HP	60.6mm
20818-025	Passivated	No	6U	261.8mm	4HP	20mm
20818-026	Passivated	No	6U	261.8mm	5HP	25mm
20818-027	Passivated	No	6U	261.8mm	6HP	30.1mm
20818-028	Passivated	No	6U	261.8mm	8HP	40.3mm
20818-029	Passivated	No	6U	261.8mm	10HP	50.5mm
20818-120	Passivated	No	6U	261.8mm	12HP	60.6mm

Catalog Number	Rear Finish	Treated Edges	Rack Height	Height (H)	Rack Width	Width (W)
20818-162	Passivated	No	6U	261.8mm	7HP	35.2mm

Table 3/3				
Catalog Number	Complies With	Flammability Rating	Package Quantity	Finish
20818-017	EN 45545-2, R22-R24, HL3, IEC 60297-3-101	UL® 94V-0	1	Anodized, Passivated
20818-018	EN 45545-2, R22-R24, HL3, IEC 60297-3-101	UL® 94V-0	1	Anodized, Passivated
20818-019	EN 45545-2, R22-R24, HL3, IEC 60297-3-101	UL® 94V-0	1	Anodized, Passivated
20818-020	EN 45545-2, R22-R24, HL3, IEC 60297-3-101	UL® 94V-0	1	Anodized, Passivated
20818-021	EN 45545-2, R22-R24, HL3, IEC 60297-3-101	UL® 94V-0	1	Anodized, Passivated
20818-022	EN 45545-2, R22-R24, HL3, IEC 60297-3-101	UL® 94V-0	1	Anodized, Passivated
20818-023	EN 45545-2, R22-R24, HL3, IEC 60297-3-101	UL® 94V-0	1	Anodized, Passivated
20818-024	EN 45545-2, R22-R24, HL3, IEC 60297-3-101	UL® 94V-0	1	Anodized, Passivated
20818-025	EN 45545-2, R22-R24, HL3, IEC 60297-3-101	UL® 94V-0	1	Anodized, Passivated
20818-026	EN 45545-2, R22-R24, HL3, IEC 60297-3-101	UL® 94V-0	1	Anodized, Passivated
20818-027	EN 45545-2, R22-R24, HL3, IEC 60297-3-101	UL® 94V-0	1	Anodized, Passivated
20818-028	EN 45545-2, R22-R24, HL3, IEC 60297-3-101	UL® 94V-0	1	Anodized, Passivated
20818-029	EN 45545-2, R22-R24, HL3, IEC 60297-3-101	UL® 94V-0	1	Anodized, Passivated
20818-120	EN 45545-2, R22-R24, HL3, IEC 60297-3-101	UL® 94V-0	1	Anodized, Passivated
20818-162	EN 45545-2, R22-R24, HL3, IEC 60297-3-101	UL® 94V-0	1	Anodized, Passivated

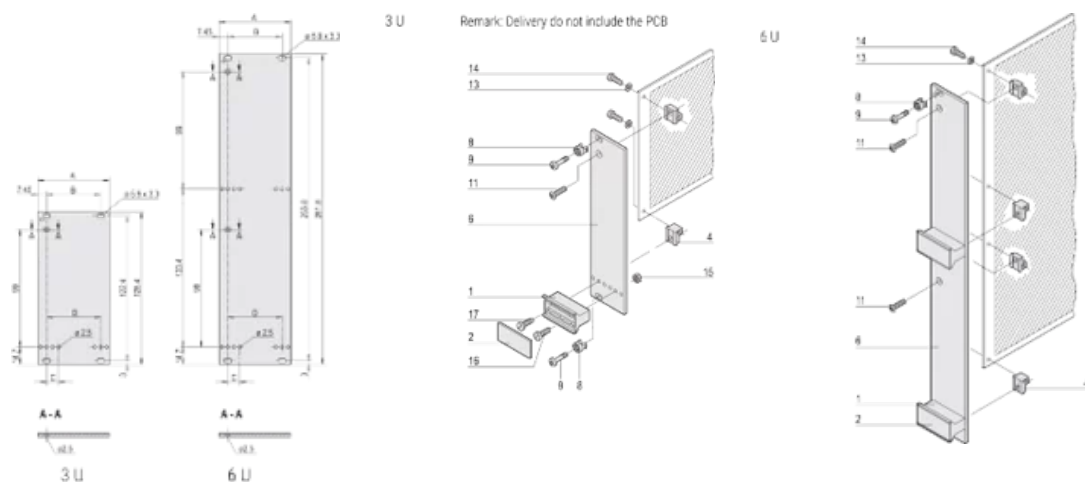

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
schroff.nvent.com

Europe

Straubenhardt, Germany
 +49.7082.794.0
 Betschdorf, France
 +33.3.88.90.64.90
 Warsaw, Poland
 +48.22.209.98.35
 Assago, Italy
 +39.02.932.7141
 Chat with us:
schroff.nvent.com

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
schroff.nvent.com

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
schroff.nvent.com



Our powerful portfolio of brands:

nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF

TRACER