



# FCS HEIGHT ADJUSTABLE LOOP HANGER



## CERTIFICATIONS



## FEATURES

- Recommended for the suspension of stationary non-insulated fire sprinkler pipe
- Redesigned strap and cup nut minimize friction for easier adjustment up and down the threaded rod (1/2" to 4" sizes)
- Formed tips on the upper strap simplify disassembly and reassembly of the hanger
- Rolled edges on the strap help to guide the pipe through, limiting binding and damage to metal or plastic pipe
- Package includes all necessary hardware for installation

## SPECIFICATIONS

- Finish:** Electrogalvanized
- Material:** Steel

| Table 1/3      |                |           |                 |       |                     |               |
|----------------|----------------|-----------|-----------------|-------|---------------------|---------------|
| Catalog Number | Article Number | Pipe Size | Pipe Size Range | NB/DN | Outer Diameter (OD) | Rod Size (RS) |
| FCS0075M10     | 597968         | 3/4"      | 0.75 in         | 20    | 27 mm               | 10            |
| FCS0075M8      | 597962         | 3/4"      | 0.75 in         | 20    | 27 mm               | 8             |


| Catalog Number | Article Number | Pipe Size | Pipe Size Range | NB/DN | Outer Diameter (OD) | Rod Size(RS) |
|----------------|----------------|-----------|-----------------|-------|---------------------|--------------|
| FCS0100M10     | 597969         | 1"        | 1 in            | 25    | 34 mm               | 10           |
| FCS0100M8      | 597963         | 1"        | 1 in            | 25    | 34 mm               | 8            |
| FCS0125M10     | 597971         | 1 1/4"    | 1.25 in min     | 32    | 43 mm               | 10           |
| FCS0125M8      | 597964         | 1 1/4"    | 1.25 in min     | 32    | 43 mm               | 8            |
| FCS0150M10     | 597972         | 1 1/2"    | 1.5 in          | 40    | 48 mm               | 10           |
| FCS0150M8      | 597965         | 1 1/2"    | 1.5 in          | 40    | 48 mm               | 8            |
| FCS0200M10     | 597973         | 2"        | 2 in min        | 50    | 60 mm               | 10           |
| FCS0200M8      | 597966         | 2"        | 2 in min        | 50    | 60 mm               | 8            |
| FCS0250M10     | 597974         | 2 1/2"    | 2.5 in          | 65    | 76 mm               | 10           |
| FCS0300M10     | 597975         | 3"        | 3 in            | 80    | 89 mm               | 10           |
| FCS0400M10     | 597976         | 4"        | 4 in            | 100   | 114 mm              | 10           |
| FCS0500M12     | 597977         | 5"        | 5 in            | 125   | 140 mm              | 12           |
| FCS0600M12     | 597978         | 6"        | 6 in            | 150   | 165 mm              | 12           |
| FCS0800M16     | 597979         | 8"        | 8 in            | 200   | 219 mm              | 16           |
| FCS1000M20     | 597981         | 10"       | 10 in           | 250   | 273 mm              | 20           |

| Table 2/3      |                |           |        |        |       |             |
|----------------|----------------|-----------|--------|--------|-------|-------------|
| Catalog Number | Article Number | Width (W) | A      | B      | C     | Wrench Size |
| FCS0075M10     | 597968         | 10 mm     | 76 mm  | 31 mm  | 17 mm | 15 mm       |
| FCS0075M8      | 597962         | 10 mm     | 74 mm  | 31 mm  | 17 mm | 13 mm       |
| FCS0100M10     | 597969         | 10 mm     | 87 mm  | 36 mm  | 19 mm | 15 mm       |
| FCS0100M8      | 597963         | 10 mm     | 85 mm  | 36 mm  | 19 mm | 13 mm       |
| FCS0125M10     | 597971         | 10 mm     | 91 mm  | 36 mm  | 15 mm | 15 mm       |
| FCS0125M8      | 597964         | 10 mm     | 89 mm  | 36 mm  | 15 mm | 13 mm       |
| FCS0150M10     | 597972         | 10 mm     | 99 mm  | 41 mm  | 17 mm | 15 mm       |
| FCS0150M8      | 597965         | 10 mm     | 97 mm  | 41 mm  | 17 mm | 13 mm       |
| FCS0200M10     | 597973         | 10 mm     | 114 mm | 50 mm  | 20 mm | 15 mm       |
| FCS0200M8      | 597966         | 10 mm     | 112 mm | 50 mm  | 20 mm | 13 mm       |
| FCS0250M10     | 597974         | 10 mm     | 142 mm | 68 mm  | 30 mm | 15 mm       |
| FCS0300M10     | 597975         | 10 mm     | 164 mm | 83 mm  | 39 mm | 15 mm       |
| FCS0400M10     | 597976         | 10 mm     | 206 mm | 112 mm | 55 mm | 15 mm       |
| FCS0500M12     | 597977         | 15 mm     | 227 mm | 114 mm | 44 mm | 18 mm       |
| FCS0600M12     | 597978         | 15 mm     | 272 mm | 146 mm | 63 mm | 18 mm       |

| Catalog Number | Article Number | Width (W) | A      | B      | C      | Wrench Size |
|----------------|----------------|-----------|--------|--------|--------|-------------|
| FCS0800M16     | 597979         | 25 mm     | 349 mm | 184 mm | 75 mm  | 24 mm       |
| FCS1000M20     | 597981         | 25 mm     | 480 mm | 279 mm | 143 mm | 30 mm       |

| Table 3/3      |                |                                                   |
|----------------|----------------|---------------------------------------------------|
| Catalog Number | Article Number | Certifications                                    |
| FCS0075M10     | 597968         | FM Approved, Pipe Hanger Components, VdS G4050054 |
| FCS0075M8      | 597962         | VdS G4050054                                      |
| FCS0100M10     | 597969         | FM Approved, Pipe Hanger Components, VdS G4050054 |
| FCS0100M8      | 597963         | VdS G4050054                                      |
| FCS0125M10     | 597971         | FM Approved, Pipe Hanger Components, VdS G4050054 |
| FCS0125M8      | 597964         | VdS G4050054                                      |
| FCS0150M10     | 597972         | FM Approved, Pipe Hanger Components, VdS G4050054 |
| FCS0150M8      | 597965         | VdS G4050054                                      |
| FCS0200M10     | 597973         | FM Approved, Pipe Hanger Components, VdS G4050054 |
| FCS0200M8      | 597966         | VdS G4050054                                      |
| FCS0250M10     | 597974         | FM Approved, Pipe Hanger Components, VdS G4050054 |
| FCS0300M10     | 597975         | FM Approved, Pipe Hanger Components, VdS G4050054 |
| FCS0400M10     | 597976         | FM Approved, Pipe Hanger Components, VdS G4050054 |
| FCS0500M12     | 597977         | FM Approved, Pipe Hanger Components, VdS G4050054 |
| FCS0600M12     | 597978         | FM Approved, Pipe Hanger Components, VdS G4050054 |
| FCS0800M16     | 597979         | FM Approved, Pipe Hanger Components, VdS G4050054 |
| FCS1000M20     | 597981         | VdS G4050054                                      |

DIAGRAMS

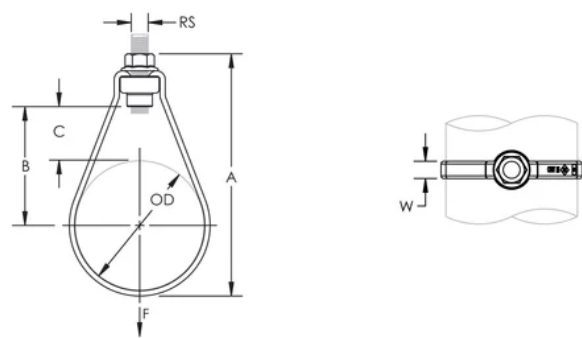

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

**North America**  
+1.800.753.9221  
Option 1 – Customer Care  
Option 2 – Technical Support

**Europe**  
Netherlands:  
+31 800-0200135  
France:  
+33 800 901 793

**Europe**  
Germany:  
800 1890272  
Other Countries:  
+31 13 5835404

**APAC**  
Shanghai:  
+ 86 21 2412 1618/19  
Sydney:  
+61 2 9751 8500



Our powerful portfolio of brands:  
**nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF**  
**TRACER**