


## NVENT CADDY MACROFIX INSULATED M8

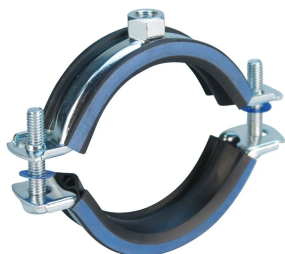

### CERTIFICATIONS



### FEATURES

Return-lip on the hanger prevents the rubber from detaching, eliminating rework during installation

Plastic washer prevents screws from falling out during installation

Combo head bolt works with slotted, hex, or Phillips drivers

Longer ears position the screw farther from the hanger, improving tool clearance when the screw is tightened

Screw length has been optimized to accommodate an increased pipe range, reducing inventory

Category II noise reduction according to DIN EN ISO 3822-1

Compliant for sound insulation design according to DIN 4109

Reaction-to-fire classification is "E" in compliance with DIN EN 13501-1

### SPECIFICATIONS

**Finish:** Electrogalvanized

**Material:** EPDM-SBR Rubber;Steel

**Temperature:** -50 to 110 °C

Table 1/2

Catalog Number	Article Number	Outer Diameter (OD)	Pipe Size	NB/DN	Rod Size (RS)	Width (W)
MFE015	586201	11 - 15 mm	1/4"	8	8	20 mm
MFE019	586202	15 - 19 mm	3/8"	10	8	20 mm
MFE025	586203	19 - 25 mm	1/2"	15	8	20 mm
MFE031	586204	25 - 31 mm	3/4"	20	8	20 mm
MFE037	586205	31 - 37 mm	1"	25	8	20 mm
MFE044	586206	37 - 44 mm	1 1/4"	32	8	20 mm
MFE050	586207	44 - 50 mm	1 1/2"	40	8	20 mm
MFE058	586208	50 - 58 mm			8	20 mm
MFE068	586209	58 - 68 mm	2"	50	8	20 mm


Table 2/2

Catalog Number	Article Number	Thickness (T)	Screw Diameter (Sc)	Screw Length (L)	Static Load (F)
MFE015	586201	1 mm	6	17mm	1000N
MFE019	586202	1 mm	6	17mm	1000N
MFE025	586203	1 mm	6	22mm	1000N
MFE031	586204	1 mm	6	22mm	1000N
MFE037	586205	1 mm	6	22mm	1000N
MFE044	586206	1 mm	6	27mm	1000N
MFE050	586207	1.25 mm	6	27mm	1500N
MFE058	586208	1.25 mm	6	27mm	1500N
MFE068	586209	1.25 mm	6	32mm	1500N

## ADDITIONAL PRODUCT DETAILS

Lining is EPDM rubber.

DIAGRAMS

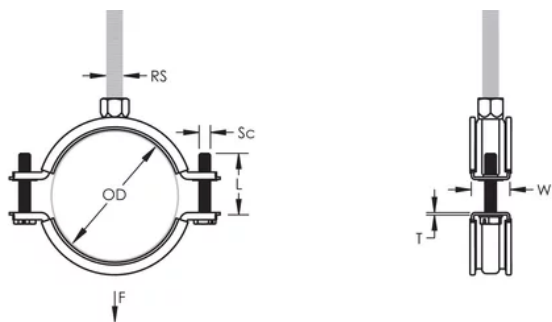

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

**North America**  
+1.800.753.9221  
Option 1 – Customer Care  
Option 2 – Technical Support

**Europe**  
Netherlands:  
+31 800-0200135  
France:  
+33 800 901 793

**Europe**  
Germany:  
800 1890272  
Other Countries:  
+31 13 5835404

**APAC**  
Shanghai:  
+ 86 21 2412 1618/19  
Sydney:  
+61 2 9751 8500



Our powerful portfolio of brands:  
**nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF**  
**TRACER**