



NVENT CADDY SPEED LINK SLDM WITH TOGGLE



FEATURES

Complete system includes wire, locking device and pre-assembled toggle end fitting

Attaches to clearance holes in a variety of structures or hanging devices

Ideal for supporting lighting fixtures

Sleek, low-profile locking device reduces visual impact

Keyless locking device is adjustable even after installation

SPECIFICATIONS

Table 1/2

| Catalog Number | Article Number | Material | Finish | Wire Rope Diameter | Wire Rope Length | A |
|----------------|----------------|----------|-------------------|--------------------|------------------|-------|
| SLDM615L2T | 196044 | Steel | Electrogalvanized | 1.5 mm | 2m | 39 mm |

Table 2/2

| Catalog Number | Article Number | B | Static Load (F) |
|----------------|----------------|------|-----------------|
| SLDM615L2T | 196044 | 5 mm | 195N |


Rod Size (RS): 6

Length (L): 7 mm

Width (W): 9.2 mm

Height (H): 24.5 mm

DIAGRAMS

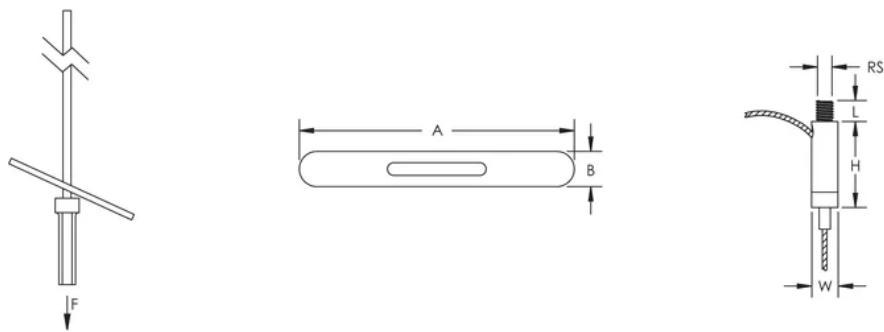

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:
nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF
TRACER