



NVENT CADDY SUPERFIX 243 M8



CERTIFICATIONS



FEATURES

Includes easy closing mechanism

Combo head bolt works with slotted, hex, or Phillips drivers

Category II noise reduction according to DIN EN ISO 3822-1

Compliant for sound insulation design according to DIN 4109

Reaction-to-fire classification is "E" in compliance with DIN EN 13501-1

SPECIFICATIONS

Color:	Black
Finish:	Electrogalvanized
Material:	Steel;EPDM-SBR Rubber
Temperature:	-50 to 110 °C

Table 1/2

Catalog Number	Article Number	Outer Diameter (OD)	Pipe Size	Pipe Size Range	NB/DN	Rod Size (RS)
----------------	----------------	---------------------	-----------	-----------------	-------	---------------

SXE019	400056	15 - 19 mm	3/8"	0.375 in	10	8
SXE023	400057	20 - 23 mm	1/2"	0.5 in	15	8
SXE028	400058	26 - 30 mm	3/4"	0.75 in	20	M8
SXE035	400059	31 - 36 mm	1"	1 in	25	8
SXE043	400060	40 - 43 mm	1 1/4"	1.25 in min	32	8
SXE052	400062	48 - 53 mm	1 1/2"	1.5 in	40	8
SXE058	589310	50 - 55 mm				8
SXE061	589320	60 - 64 mm	2"	2 in min	50	8
SXE014	400055	12 - 16 mm	1/4"	0.25 in	8	8


Table 2/2

Catalog Number	Article Number	Width (W)	Thickness (T)	Screw Diameter (Sc)	Screw Length (L)	Static Load (F)
SXE019	400056	20 mm	1.2 mm	5	25mm	1000N
SXE023	400057	20 mm	1.2 mm	5	25mm	1000N
SXE028	400058	20 mm	1.2 mm	5	25mm	1000N
SXE035	400059	20 mm	1.2 mm	5	30mm	1000N
SXE043	400060	20 mm	1.2 mm	5	30mm	1000N
SXE052	400062	20 mm	1.2 mm	5	30mm	1300N
SXE058	589310	20 mm	1.2 mm	5	30mm	1300N
SXE061	589320	20 mm	1.2 mm	5	30mm	1300N
SXE014	400055	20 mm	1.2 mm	5	25mm	1000N

ADDITIONAL PRODUCT DETAILS

Lining is EPDM rubber.

DIAGRAMS

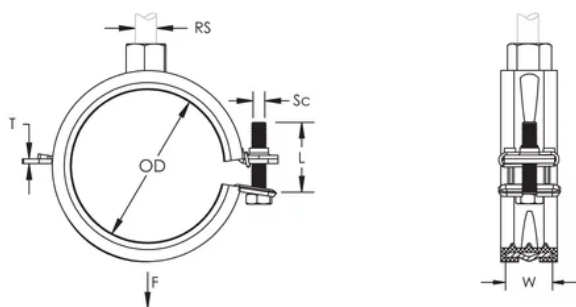

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:
nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF
TRACER