


FRONT PANEL, FLAT, UNSHIELDED, D-SUB CUTOUTS

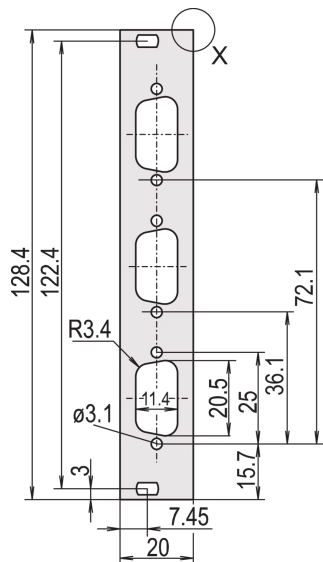

Flat front panel with cutout for D-Sub connectors. Unshielded version.

CERTIFICATIONS



FEATURES

Non-shielded version

Aluminum, 2.5 mm, front anodized, rear conductive

SPECIFICATIONS

| Table 1/3 | | | | | | |
|----------------|---------------|--------------|-------------|---------------|------------|------------------|
| Catalog Number | Treated Edges | Front Finish | Rear Finish | EMC Shielding | Rack Width | Package Quantity |
| 30118-341 | No | Anodized | Conductive | No | 4 HP | 5 |
| 30118-342 | No | Anodized | Conductive | No | 4 HP | 5 |
| 30118-343 | No | Anodized | Conductive | No | 4 HP | 5 |
| 30118-344 | No | Anodized | Conductive | No | 4 HP | 5 |

| Catalog Number | Treated Edges | Front Finish | Rear Finish | EMC Shielding | Rack Width | Package Quantity |
|----------------|---------------|--------------|-------------|---------------|------------|------------------|
| 30118-345 | No | Anodized | Conductive | No | 4 HP | 5 |
| 30118-346 | No | Anodized | Conductive | No | 4 HP | 5 |
| 30118-347 | No | Anodized | Conductive | No | 4 HP | 5 |

| Table 2/3 | | | | | | |
|----------------|----------|--------------|----------------------------|-------------|-------|---------------------------------|
| Catalog Number | Height | Product Type | Type | Rack Height | Width | Complies With |
| 30118-341 | 128.4 mm | Front Panel | Front Panel without Handle | 3 U | 20 mm | IEC 60297-3-101, IEEE 1101.1/10 |
| 30118-342 | 128.4 mm | Front Panel | Front Panel without Handle | 3 U | 20 mm | IEC 60297-3-101, IEEE 1101.1/10 |
| 30118-343 | 128.4 mm | Front Panel | Front Panel without Handle | 3 U | 20 mm | IEC 60297-3-101, IEEE 1101.1/10 |
| 30118-344 | 128.4 mm | Front Panel | Front Panel without Handle | 3 U | 20 mm | IEC 60297-3-101, IEEE 1101.1/10 |
| 30118-345 | 128.4 mm | Front Panel | Front Panel without Handle | 3 U | 20 mm | IEC 60297-3-101, IEEE 1101.1/10 |
| 30118-346 | 128.4 mm | Front Panel | Front Panel without Handle | 3 U | 20 mm | IEC 60297-3-101, IEEE 1101.1/10 |
| 30118-347 | 128.4 mm | Front Panel | Front Panel without Handle | 3 U | 20 mm | IEC 60297-3-101, IEEE 1101.1/10 |

| Table 3/3 | | |
|----------------|----------------|----------|
| Catalog Number | Mounting | Material |
| 30118-341 | Screw-on Front | Aluminum |
| 30118-342 | Screw-on Front | Aluminum |
| 30118-343 | Screw-on Front | Aluminum |
| 30118-344 | Screw-on Front | Aluminum |
| 30118-345 | Screw-on Front | Aluminum |
| 30118-346 | Screw-on Front | Aluminum |
| 30118-347 | Screw-on Front | Aluminum |

ADDITIONAL PRODUCT DETAILS

Delivery is in standard pack multiples. Pricing is per individual item.

Please order fixing material (sleeves, collar screws) separately.

Please take into consideration that deliveries may be carried out in the stated SPQs (SPQ, e.g. 5 pieces, 10 pieces, 50 pieces, etc.). Differing order quantities (e.g. 2 pieces) may be changed to the next possible delivery quantity = Standard Pack Quantity.

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:
nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF
TRACER