


FRONT PANEL, UNSHIELDED, BOTTOM HINGED

Unshielded front panel bottom hinged.

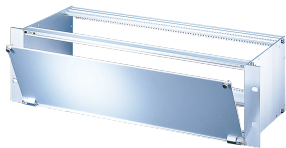

CERTIFICATIONS



FEATURES

Front panel can be unhinged at 135° (not RatiopacPRO) opening angle

Enables mounting on horizontal rails

SPECIFICATIONS

Table 1/3

Catalog Number	Treated Edges	Front Finish	Rear Finish	EMC Shielding	Rack Width	Package Quantity
20838-271	No	Anodized	Conductive	No	42 HP	1
20838-272	No	Anodized	Conductive	No	63 HP	1
20838-273	No	Anodized	Conductive	No	84 HP	1
20838-274	No	Anodized	Conductive	No	42 HP	1
20838-275	No	Anodized	Conductive	No	63 HP	1
20838-276	No	Anodized	Conductive	No	84 HP	1
20838-277	No	Anodized	Conductive	No	42 HP	1
20838-278	No	Anodized	Conductive	No	63 HP	1

Catalog Number	Treated Edges	Front Finish	Rear Finish	EMC Shielding	Rack Width	Package Quantity
20838-279	No	Anodized	Conductive	No	84 HP	1
20838-280	No	Anodized	Conductive	No	28 HP	1

Table 2/3						
Catalog Number	Height	Product Type	Type	Rack Height	Width	Complies With
20838-271	128.4 mm	Front Panel	Front Panel without Handle	3 U	213 mm	IEC 60297-3-101, IEEE 1101.1/10
20838-272	128.4 mm	Front Panel	Front Panel without Handle	3 U	319.7 mm	IEC 60297-3-101, IEEE 1101.1/10
20838-273	128.4 mm	Front Panel	Front Panel without Handle	3 U	426.4 mm	IEC 60297-3-101, IEEE 1101.1/10
20838-274	261.8 mm	Front Panel	Front Panel without Handle	6 U	213 mm	IEC 60297-3-101, IEEE 1101.1/10
20838-275	261.8 mm	Front Panel	Front Panel without Handle	6 U	319.7 mm	IEC 60297-3-101, IEEE 1101.1/10
20838-276	261.8 mm	Front Panel	Front Panel without Handle	6 U	426.4 mm	IEC 60297-3-101, IEEE 1101.1/10
20838-277	172.9 mm	Front Panel	Front Panel without Handle	4 U	213 mm	IEC 60297-3-101, IEEE 1101.1/10
20838-278	172.9 mm	Front Panel	Front Panel without Handle	4 U	319.7 mm	IEC 60297-3-101, IEEE 1101.1/10
20838-279	172.9 mm	Front Panel	Front Panel without Handle	4 U	426.4 mm	IEC 60297-3-101, IEEE 1101.1/10
20838-280	128.4 mm	Front Panel	Front Panel without Handle	3 U	141.9 mm	IEC 60297-3-101, IEEE 1101.1/10

Table 3/3		
Catalog Number	Mounting	Material
20838-271	Hinged, Bottom	Aluminum
20838-272	Hinged, Bottom	Aluminum
20838-273	Hinged, Bottom	Aluminum

Catalog Number	Mounting	Material
20838-274	Hinged, Bottom	Aluminum
20838-275	Hinged, Bottom	Aluminum
20838-276	Hinged, Bottom	Aluminum
20838-277	Hinged, Bottom	Aluminum
20838-278	Hinged, Bottom	Aluminum
20838-279	Hinged, Bottom	Aluminum
20838-280	Hinged, Bottom	Aluminum

ADDITIONAL PRODUCT DETAILS

Front panel can be removed in opened position (> 135°).

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:
nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF
TRACER