



# NVENT CADDY SPEED LINK Y-TOGGLE WITH EYELET EXTENSION



## CERTIFICATIONS



## FEATURES

Attaches to clearance holes in a variety of structures or hanging devices

Ideal for supporting lighting fixtures

Y-design provides improved stability

## SPECIFICATIONS

<b>Static Load Safety Factor:</b>	5:1
<b>Finish:</b>	Electrogalvanized
<b>Material:</b>	Steel

Table 1/2

Catalog Number	Article Number	Wire Rope Diameter	Wire Rope "Y" Length (YL)	A	B	Static Load (F)
SLD15Y200	195999	1.5 mm	0.2m	39 mm	5 mm	195N
SLD15Y300	196000	1.5 mm	0.3m	39 mm	5 mm	195N
SLD15Y500	195960	1.5 mm	0.5m	39 mm	5 mm	195N

Catalog Number	Article Number	Wire Rope Diameter	Wire Rope "Y" Length (YL)	A	B	Static Load (F)
SLD2Y300	196036	2 mm	0.3m	42 mm	8 mm	440N
SLD2Y500	176870	2 mm	0.5m	42 mm	8 mm	440N


Table 2/2

Catalog Number	Article Number	Packing Quantity	Certifications
SLD15Y200	195999	1.0000	cUL, UL
SLD15Y300	196000	1.0000	cUL, UL
SLD15Y500	195960	1.0000	cUL, ITB, UL
SLD2Y300	196036	1.0000	cUL, UL
SLD2Y500	176870	1.0000	cUL, ITB, UL

## ADDITIONAL PRODUCT DETAILS

nVent CADDY Speed Link locking device not included.

## DIAGRAMS

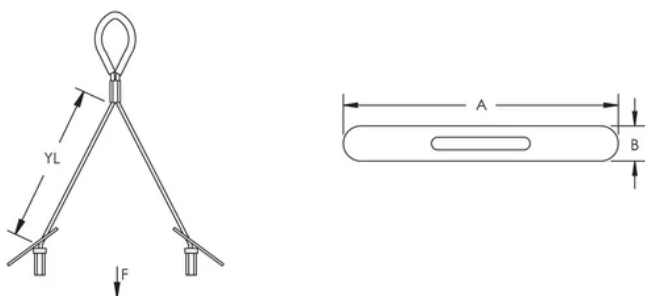

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

#### North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical Support

#### Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

#### Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

#### APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:  
**nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF**  
**TRACER**