

## 19" FRONT PANEL



Front panels are Al anodized, colours light grey (RAL 7035) or black grey (RAL 7021).

### CERTIFICATIONS



### FEATURES

Al anodized, 3 mm

### SPECIFICATIONS

**Accessory Type:** Front panel

Table 1/3

Catalog Number	Type	Mounting	Front Finish	Rear Finish	Treated Edges	EMC Shielding
30118-299	19" Front Panel	Screw-on Front	Painted	Painted		No
30118-948	19" Front Panel	Screw-on Front	Painted	Painted		No
30219-098	19" Front Panel	Screw-on Front	Anodized	Anodized	No	No
40304-074	19" Front Panel	Screw-on Front	Anodized	Anodized	Yes	No
30118-301	19" Front Panel	Screw-on Front	Painted	Painted		No
30118-302	19" Front Panel	Screw-on Front	Painted	Painted		No
30118-303	19" Front Panel	Screw-on Front	Painted	Painted		No

Catalog Number	Type	Mounting	Front Finish	Rear Finish	Treated Edges	EMC Shielding
30118-304	19" Front Panel	Screw-on Front	Painted	Painted		No
30118-305	19" Front Panel	Screw-on Front	Painted	Painted		No
30118-306	19" Front Panel	Screw-on Front	Painted	Painted		No
30118-307	19" Front Panel	Screw-on Front	Painted	Painted		No
30118-308	19" Front Panel	Screw-on Front	Painted	Painted		No
30118-309	19" Front Panel	Screw-on Front	Painted	Painted		No
30118-949	19" Front Panel	Screw-on Front	Painted	Painted		No
30118-950	19" Front Panel	Screw-on Front	Painted	Painted		No
30118-951	19" Front Panel	Screw-on Front	Painted	Painted		No
30118-952	19" Front Panel	Screw-on Front	Painted	Painted		No
30118-953	19" Front Panel	Screw-on Front	Painted	Painted		No
30118-954	19" Front Panel	Screw-on Front	Painted	Painted		No
30118-955	19" Front Panel	Screw-on Front	Painted	Painted		No
30118-956	19" Front Panel	Screw-on Front	Painted	Painted		No
30118-957	19" Front Panel	Screw-on Front	Painted	Painted		No
30219-101	19" Front Panel	Screw-on Front	Anodized	Anodized	No	No
30219-104	19" Front Panel	Screw-on Front	Anodized	Anodized	No	No
30219-107	19" Front Panel	Screw-on Front	Anodized	Anodized	No	No
30219-110	19" Front Panel	Screw-on Front	Anodized	Anodized	No	No
30219-113	19" Front Panel	Screw-on Front	Anodized	Anodized	No	No
30219-137	19" Front Panel	Screw-on Front	Anodized	Anodized	No	No
30219-138	19" Front Panel	Screw-on Front	Anodized	Anodized	No	No
30219-143	19" Front Panel	Screw-on Front	Anodized	Anodized	No	No
30219-144	19" Front Panel	Screw-on Front	Anodized	Anodized	No	No
40304-075	19" Front Panel	Screw-on Front	Anodized	Anodized	Yes	No
40304-076	19" Front Panel	Screw-on Front	Anodized	Anodized	Yes	No
40304-077	19" Front Panel	Screw-on Front	Anodized	Anodized	Yes	No
40304-078	19" Front Panel	Screw-on Front	Anodized	Anodized	Yes	No
40304-079	19" Front Panel	Screw-on Front	Anodized	Anodized	Yes	No
40304-080	19" Front Panel	Screw-on Front	Anodized	Anodized	Yes	No
40304-081	19" Front Panel	Screw-on Front	Anodized	Anodized	Yes	No
40304-082	19" Front Panel	Screw-on Front	Anodized	Anodized	Yes	No
40304-083	19" Front Panel	Screw-on Front	Anodized	Anodized	Yes	No

Table 2/3

Catalog Number	Rack Width	Product Type	Height (H)	Works With	Rack Height	Package Quantity
30118-299	95HP	Front Panel	43.6mm	Cabinet, Wallmount Cases, 19" cases	1U	1
30118-948	95HP	Front Panel	43.6mm	Cabinet, Wallmount Cases, 19" cases	1U	1
30219-098	95HP	Front Panel	43.6mm	Cabinet, Wallmount Cases, 19" cases	1U	1
40304-074	95HP	Front Panel	43.6mm	Cabinet, Wallmount Cases, 19" cases	1U	1
30118-301	95HP	Front Panel	88.1mm	Cabinet, Wallmount Cases, 19" cases	2U	1
30118-302	95HP	Front Panel	132.5mm	Cabinet, Wallmount Cases, 19" cases	3U	1
30118-303	95HP	Front Panel	177mm	Cabinet, Wallmount Cases, 19" cases	4U	1
30118-304	95HP	Front Panel	221.4mm	Cabinet, Wallmount Cases, 19" cases	5U	1
30118-305	95HP	Front Panel	265.9mm	Cabinet, Wallmount Cases, 19" cases	6U	1
30118-306	95HP	Front Panel	310.3mm	Cabinet, Wallmount Cases, 19" cases	7U	1
30118-307	95HP	Front Panel	354.8mm	Cabinet, Wallmount Cases, 19" cases	8U	1

Catalog Number	Rack Width	ProductType	Height (H)	Works With	Rack Height	Package Quantity
30118-308	95HP	Front Panel	399.2mm	Cabinet, Wallmount Cases, 19" cases	9U	1
30118-309	95HP	Front Panel	443.7mm	Cabinet, Wallmount Cases, 19" cases	10U	1
30118-949	95HP	Front Panel	88.1mm	Cabinet, Wallmount Cases, 19" cases	2U	1
30118-950	95HP	Front Panel	132.5mm	Cabinet, Wallmount Cases, 19" cases	3U	1
30118-951	95HP	Front Panel	177mm	Cabinet, Wallmount Cases, 19" cases	4U	1
30118-952	95HP	Front Panel	221.4mm	Cabinet, Wallmount Cases, 19" cases	5U	1
30118-953	95HP	Front Panel	265.9mm	Cabinet, Wallmount Cases, 19" cases	6U	1
30118-954	95HP	Front Panel	310.3mm	Cabinet, Wallmount Cases, 19" cases	7U	1
30118-955	95HP	Front Panel	354.8mm	Cabinet, Wallmount Cases, 19" cases	8U	1
30118-956	95HP	Front Panel	399.2mm	Cabinet, Wallmount Cases, 19" cases	9U	1
30118-957	95HP	Front Panel	443.7mm	Cabinet, Wallmount Cases, 19" cases	10U	1

Catalog Number	Rack Width	ProductType	Height (H)	Works With	Rack Height	Package Quantity
30219-101	95HP	Front Panel	88.1mm	Cabinet, Wallmount Cases, 19" cases	2U	1
30219-104	95HP	Front Panel	132.5mm	Cabinet, Wallmount Cases, 19" cases	3U	1
30219-107	95HP	Front Panel	177mm	Cabinet, Wallmount Cases, 19" cases	4U	1
30219-110	95HP	Front Panel	221.4mm	Cabinet, Wallmount Cases, 19" cases	5U	1
30219-113	95HP	Front Panel	265.9mm	Cabinet, Wallmount Cases, 19" cases	6U	1
30219-137	95HP	Front Panel	310.3mm	Cabinet, Wallmount Cases, 19" cases	7U	1
30219-138	95HP	Front Panel	354.8mm	Cabinet, Wallmount Cases, 19" cases	8U	1
30219-143	95HP	Front Panel	399.2mm	Cabinet, Wallmount Cases, 19" cases	9U	1
30219-144	95HP	Front Panel	443.7mm	Cabinet, Wallmount Cases, 19" cases	10U	1
40304-075	95HP	Front Panel	88.1mm	Cabinet, Wallmount Cases, 19" cases	2U	1
40304-076	95HP	Front Panel	132.5mm	Cabinet, Wallmount Cases, 19" cases	3U	1

Catalog Number	Rack Width	ProductType	Height (H)	Works With	Rack Height	Package Quantity
40304-077	95HP	Front Panel	177mm	Cabinet, Wallmount Cases, 19" cases	4U	1
40304-078	95HP	Front Panel	221.4mm	Cabinet, Wallmount Cases, 19" cases	5U	1
40304-079	95HP	Front Panel	265.9mm	Cabinet, Wallmount Cases, 19" cases	6U	1
40304-080	95HP	Front Panel	310.3mm	Cabinet, Wallmount Cases, 19" cases	7U	1
40304-081	95HP	Front Panel	354.8mm	Cabinet, Wallmount Cases, 19" cases	8U	1
40304-082	95HP	Front Panel	399.2mm	Cabinet, Wallmount Cases, 19" cases	9U	1
40304-083	95HP	Front Panel	443.7mm	Cabinet, Wallmount Cases, 19" cases	10U	1


Table 3/3						
Catalog Number	Finish	Material	Color	Color Code	Width (W)	Depth (D)
30118-299	Powder Coated	Aluminum	Light Grey	RAL 7035	483mm	3mm
30118-948	Powder Coated	Aluminum	Black Grey	RAL 7021	483mm	3mm
30219-098	Anodized	Aluminum			483mm	3mm
40304-074	Anodized	Aluminum			483mm	4mm
30118-301	Powder Coated	Aluminum	Light Grey	RAL 7035	483mm	3mm
30118-302	Powder Coated	Aluminum	Light Grey	RAL 7035	483mm	3mm
30118-303	Powder Coated	Aluminum	Light Grey	RAL 7035	483mm	3mm
30118-304	Powder Coated	Aluminum	Light Grey	RAL 7035	483mm	3mm
30118-305	Powder Coated	Aluminum	Light Grey	RAL 7035	483mm	3mm
30118-306	Powder Coated	Aluminum	Light Grey	RAL 7035	483mm	3mm

Catalog Number	Finish	Material	Color	Color Code	Width (W)	Depth (D)
30118-307	Powder Coated	Aluminum	Light Grey	RAL 7035	483mm	3mm
30118-308	Powder Coated	Aluminum	Light Grey	RAL 7035	483mm	3mm
30118-309	Powder Coated	Aluminum	Light Grey	RAL 7035	483mm	3mm
30118-949	Powder Coated	Aluminum	Black Grey	RAL 7021	483mm	3mm
30118-950	Powder Coated	Aluminum	Black Grey	RAL 7021	483mm	3mm
30118-951	Powder Coated	Aluminum	Black Grey	RAL 7021	483mm	3mm
30118-952	Powder Coated	Aluminum	Black Grey	RAL 7021	483mm	3mm
30118-953	Powder Coated	Aluminum	Black Grey	RAL 7021	483mm	3mm
30118-954	Powder Coated	Aluminum	Black Grey	RAL 7021	483mm	3mm
30118-955	Powder Coated	Aluminum	Black Grey	RAL 7021	483mm	3mm
30118-956	Powder Coated	Aluminum	Black Grey	RAL 7021	483mm	3mm
30118-957	Powder Coated	Aluminum	Black Grey	RAL 7021	483mm	3mm
30219-101	Anodized	Aluminum			483mm	3mm
30219-104	Anodized	Aluminum			483mm	3mm
30219-107	Anodized	Aluminum			483mm	3mm
30219-110	Powder Coated	Aluminum			483mm	3mm
30219-113	Anodized	Aluminum			483mm	3mm
30219-137	Anodized	Aluminum			483mm	3mm
30219-138	Anodized	Aluminum			483mm	3mm
30219-143	Anodized	Aluminum			483mm	3mm
30219-144	Anodized	Aluminum			483mm	3mm
40304-075	Anodized	Aluminum			483mm	4mm
40304-076	Anodized	Aluminum			483mm	4mm
40304-077	Anodized	Aluminum			483mm	4mm
40304-078	Anodized	Aluminum			483mm	4mm
40304-079	Anodized	Aluminum			483mm	4mm
40304-080	Anodized	Aluminum			483mm	4mm
40304-081	Anodized	Aluminum			483mm	4mm
40304-082	Anodized	Aluminum			483mm	4mm
40304-083	Anodized	Aluminum			483mm	4mm

## ADDITIONAL PRODUCT DETAILS

Please order 19" assembly kit separately.

DIAGRAMS

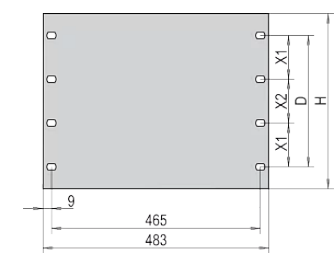

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:  
**nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF**  
**TRACER**