



PUSH IN CONDUIT CLAMP



FEATURES

- Push-in installation of conduit
- Eliminates need for offset bending conduit
- May be used for either vertical or horizontal installations


SPECIFICATIONS

- Finish:** nVent CADDY Armour
- Material:** Spring Steel

Table 1/1

Catalog Number	Article Number	Outer Diameter (OD)	Hole Size (HS)	Hole Type	Ultimate Static Load 1 (F1)	Ultimate Static Load 2 (F2)
12P4I		19.1 mm	6.4 mm	Threaded	110N	65N
16P4I		25.4 mm	6.4 mm	Threaded	110N	65N
8P4I		18 - 22 mm	6.4 mm	Threaded	110N	65N
12P	171150	22 - 30 mm	7 mm	Plain	110N	65N
16P	171170	30 - 35 mm	7 mm	Plain	110N	65N
8P	171130	18 - 22 mm	7 mm	Plain	110N	65N

DIAGRAMS

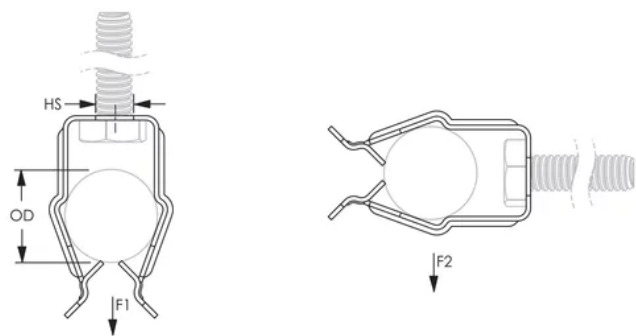

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:
nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF
TRACER