

BINDING POST LUG



FEATURES


- Tin plated for corrosion prevention
- Annealed copper eases the crimping operation

SPECIFICATIONS

Table 1/2						
Catalog Number	Material	Finish	Length (L)	Width (W)	Hole Size (HS)	Conductor Size
A2412J	Copper	Tinned	36 mm	12 mm	6.5 mm	3/16" Stranded

Table 2/2	
Catalog Number	Tool/Die Type
A2412J	SBT031DJ Manual Compression Tool/No die required

DIAGRAMS

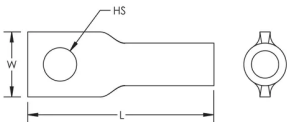

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:
nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF
TRACER