


PLUG-IN UNIT KIT WITH IET HANDLE, SHIELDED, BLACK 3 U

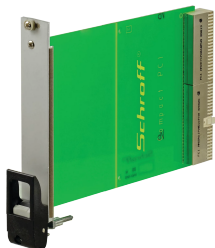

Plug-in unit, with IET inserter/extractor black handle, 3 U, front assembly. The U-shaped front panel enable shielding with a textile gasket.

CERTIFICATIONS



FEATURES

U-shaped front panel for textile gasket

Suitable for insertion and extraction forces up to 700 N (per pair)

Enable the installation of a microswitch

Enable the installation of coding pegs in accordance with IEC 60297-3-103/ IEEE 1101.10

SPECIFICATIONS

Table 1/3

| Catalog Number | Type | Handle Type | Mounting | EMC Shielding | EMC Gasket Type | Material |
|----------------|-------------------------------|-------------|----------------|---------------|-----------------|----------|
| 20848-763 | Front Panel with Handle (PIU) | IET | Screw-on Front | Yes | Textile | Aluminum |
| 20848-764 | Front Panel with Handle (PIU) | IET | Screw-on Front | Yes | Textile | Aluminum |
| 20848-765 | Front Panel with Handle (PIU) | IET | Screw-on Front | Yes | Textile | Aluminum |

Table 2/3

| Catalog Number | Front Finish | Rear Finish | Treated Edges | Rack Height | Height | Rack Width |
|----------------|--------------|-------------|---------------|-------------|---------|------------|
| 20848-763 | Anodized | Etched | No | 3U | 128.4mm | 4HP |
| 20848-764 | Anodized | Etched | No | 3U | 128.4mm | 8HP |
| 20848-765 | Anodized | Etched | No | 3U | 128.4mm | 12HP |

Table 3/3

| Catalog Number | Width | Complies With | Package Quantity | Finish |
|----------------|--------|--|------------------|----------------------|
| 20848-763 | 20mm | IEC 60297-3-102, IEEE 1101.10, IEC 60297-3-103, IEEE 1101.1/11 | 1 | Anodized, Passivated |
| 20848-764 | 40.3mm | IEC 60297-3-102, IEEE 1101.10, IEC 60297-3-103, IEEE 1101.1/11 | 1 | Anodized, Passivated |
| 20848-765 | 60.6mm | IEC 60297-3-102, IEEE 1101.10, IEC 60297-3-103, IEEE 1101.1/11 | 1 | Anodized, Passivated |

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
schroff.nvent.com

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
schroff.nvent.com

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
schroff.nvent.com

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
schroff.nvent.com



Our powerful portfolio of brands:
nVent.com **CADDY ERICO HOFFMAN RAYCHEM SCHROFF**
TRACER