


## JOINT BOND T6 COMPLETE WELDER PAIR, SIGNAL, 3/4" TAB BOND TERMINAL STYLE, 3/16" BONDSTRAND

### CATALOG NUMBER

**SBTBT6C**

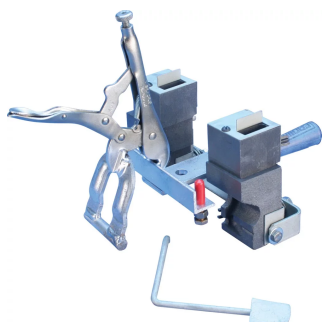

### FEATURES

Complete welder assembly provides a convenient means of attaching jumper bonds to the head of the rail, across the joint

Connection is made within the confines of the splice bar

Includes mold cleaner

### PRODUCT ATTRIBUTES

Material: Steel; Graphite; Thermoplastic

Rail Type: 85 lb to 141 lb T-Rail Sections

Bond Terminal Style: 3/4" Tab

Conductor Size: 3/16" Bondstrand

Conductor Outer Diameter, Nominal: 4.76mm

Bond Length: 190.5mm

Welder Style: T6

Mold Only: No

Replacement Mold: SBS5838

Welding Material: SB25 x 2, Sold Separately

Frame: SBS5838F, Sold Separately

Bond Clip: SBS2659 x 2, Sold Separately

## WARNING

---

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

⚠ WARNING: This product can expose you to chemicals including diisononyl phthalate, which is known to the State of California to cause cancer. For more information go to [www.P65Warnings.ca.gov](http://www.P65Warnings.ca.gov).



Our powerful portfolio of brands:  
**nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF**  
**TRACER**