



## NVENT CADDY MACROFIX PLUS NI EZ WITH EASY CLOSURE



### CERTIFICATIONS



### FEATURES

Contains easy closing mechanism

Plastic washers help prevent crushing the CPVC or plastic pipe and assure a floating fit

Flared edges and specially designed welding area help protect CPVC piping

Ideal for installations where space is limited and require services to be ran close to the attachment surface

Suitable for 3/4" - 2" (20 - 50 DN) steel sprinkler pipe

Eliminates the need to seismically brace when drops are kept within 6" (150 mm) of the attachment surface

Combo head bolt works with slotted, hex, or Phillips drivers

Conforms with Manufacturers Standardization Society (MSS) SP-58 (Type 12)

### SPECIFICATIONS

**Finish:** Electrogalvanized

**Material:** Steel


Table 1/2

| Catalog Number | Article Number | Pipe Size | NB/DN | Outer Diameter (OD) | Rod Size (RS) | Width (W) |
|----------------|----------------|-----------|-------|---------------------|---------------|-----------|
| MPZ020         | 595052         | 1/2"      | 15    | 20.0 - 21.3 mm      | 10            | 30 mm     |
| MPZ025         | 595053         | 3/4"      | 20    | 25.0 - 26.9 mm      | 10            | 30 mm     |
| MPZ032         | 595054         | 1"        | 25    | 32.0 - 33.7 mm      | 10            | 30 mm     |
| MPZ040         | 595056         | 1 1/4"    | 32    | 40.0 - 42.4 mm      | 10            | 30 mm     |
| MPZ050         | 595057         | 1 1/2"    | 40    | 48.3 - 50 mm        | 10            | 30 mm     |
| MPZ063         | 595059         | 2"        | 50    | 60.3 - 63 mm        | 10            | 30 mm     |
| MPZ075         | 595061         | 2 1/2"    | 65    | 75.0 - 76.1 mm      | 10            | 30 mm     |
| MPZ090         | 595062         | 3"        | 80    | 88.9 - 90 mm        | 10            | 30 mm     |
| MPZ110         | 595063         | 4"        | 100   | 110.0 - 114.3 mm    | 10            | 30 mm     |

Table 2/2

| Catalog Number | Article Number | Thickness (T) | Static Load (F) | Certifications                                                                |
|----------------|----------------|---------------|-----------------|-------------------------------------------------------------------------------|
| MPZ020         | 595052         | 1.5 mm        | 1125N           | AON Fire Protection, BB019, pipe hangers                                      |
| MPZ025         | 595053         | 1.5 mm        | 1125N           | AON Fire Protection, Macrofix Plus NI EZ, FM Approved, Pipe Hanger Components |
| MPZ032         | 595054         | 1.5 mm        | 1125N           | AON Fire Protection, Macrofix Plus NI EZ, FM Approved, Pipe Hanger Components |
| MPZ040         | 595056         | 1.5 mm        | 1125N           | AON Fire Protection, Macrofix Plus NI EZ, FM Approved, Pipe Hanger Components |
| MPZ050         | 595057         | 2 mm          | 1725N           | AON Fire Protection, Macrofix Plus NI EZ, FM Approved, Pipe Hanger Components |
| MPZ063         | 595059         | 2 mm          | 1725N           | AON Fire Protection, Macrofix Plus NI EZ, FM Approved, Pipe Hanger Components |
| MPZ075         | 595061         | 2 mm          | 1725N           |                                                                               |
| MPZ090         | 595062         | 2 mm          | 1725N           |                                                                               |
| MPZ110         | 595063         | 2.5 mm        | 2000N           |                                                                               |

DIAGRAMS

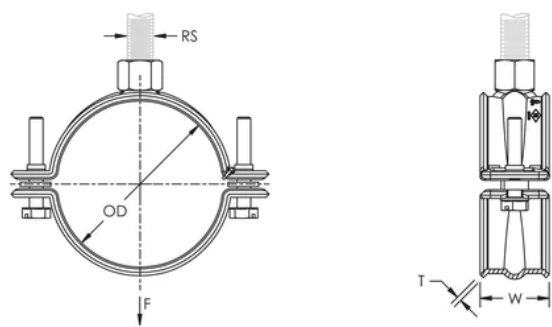

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221  
Option 1 – Customer Care  
Option 2 – Technical Support

Europe

Netherlands:  
+31 800-0200135  
France:  
+33 800 901 793

Europe

Germany:  
800 1890272  
Other Countries:  
+31 13 5835404

APAC

Shanghai:  
+ 86 21 2412 1618/19  
Sydney:  
+61 2 9751 8500



Our powerful portfolio of brands:  
**nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF**  
**TRACER**