



BRANCH LINE RESTRAINT STRUCTURE ATTACHMENT TO WOOD/CONCRETE



CERTIFICATIONS



FEATURES

Swivel barrel nut accepts 3/8" or 1/2" (M10 or M12) threaded rod

Attaches to wood or concrete where cracked concrete approval is not needed

SPECIFICATIONS

Table 1/2

| Catalog Number | Article Number | Material | Finish | Rod Size (RS) | Height (H) | Length (L) |
|----------------|----------------|----------|-------------------|---------------|------------|------------|
| CSBBRS2MEG | 402240 | Steel | Electrogalvanized | 10, 12 | 28.2 mm | 40.4 mm |


Table 2/2

| Catalog Number | Article Number | Width (W) | Screw Diameter (Sc) | Screw Length (L) | Drill Bit Diameter |
|----------------|----------------|-----------|---------------------|------------------|--------------------|
| CSBBRS2MEG | 402240 | 26.9 mm | 1/4" | 44.5mm | 5mm |

ADDITIONAL PRODUCT DETAILS

Branch line structural attachments are for restraint only and not for the hanging of fire sprinkler piping.

DIAGRAMS

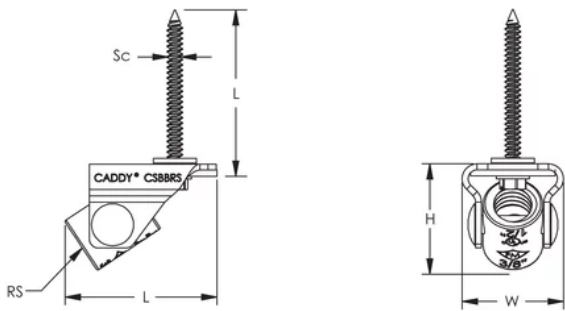

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America
+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical Support

Europe
Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe
Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC
Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500