



FCS HEIGHT ADJUSTABLE LOOP HANGER



CERTIFICATIONS



FEATURES

- Recommended for the suspension of stationary non-insulated fire sprinkler pipe
- Redesigned strap and cup nut minimize friction for easier adjustment up and down the threaded rod (1/2" to 4" sizes)
- Formed tips on the upper strap simplify disassembly and reassembly of the hanger
- Rolled edges on the strap help to guide the pipe through, limiting binding and damage to metal or plastic pipe
- Package includes all necessary hardware for installation

SPECIFICATIONS

- Finish:** Electrogalvanized
- Material:** Steel


Table 1/2						
Catalog Number	Article Number	Pipe Size	NB/DN	Outer Diameter (OD)	Rod Size (RS)	Width (W)
FCS0075M10	597968	3/4"	20	27 mm	10	10 mm
FCS0075M8	597962	3/4"	20	27 mm	8	10 mm

Catalog Number	Article Number	Pipe Size	NB/DN	Outer Diameter (OD)	Rod Size(RS)	Width (W)
FCS0100M10	597969	1"	25	34 mm	10	10 mm
FCS0100M8	597963	1"	25	34 mm	8	10 mm
FCS0125M10	597971	1 1/4"	32	43 mm	10	10 mm
FCS0125M8	597964	1 1/4"	32	43 mm	8	10 mm
FCS0150M10	597972	1 1/2"	40	48 mm	10	10 mm
FCS0150M8	597965	1 1/2"	40	48 mm	8	10 mm
FCS0200M10	597973	2"	50	60 mm	10	10 mm
FCS0200M8	597966	2"	50	60 mm	8	10 mm
FCS0250M10	597974	2 1/2"	65	76 mm	10	10 mm
FCS0300M10	597975	3"	80	89 mm	10	10 mm
FCS0400M10	597976	4"	100	114 mm	10	10 mm
FCS0500M12	597977	5"	125	140 mm	12	15 mm
FCS0600M12	597978	6"	150	165 mm	12	15 mm
FCS0800M16	597979	8"	200	219 mm	16	25 mm
FCS1000M20	597981	10"	250	273 mm	20	25 mm

Table 2/2						
Catalog Number	Article Number	A	B	C	Wrench Size	Certifications
FCS0075M10	597968	76 mm	31 mm	17 mm	15 mm	FM Approved, Pipe Hanger Components, VdS G4050054
FCS0075M8	597962	74 mm	31 mm	17 mm	13 mm	VdS G4050054
FCS0100M10	597969	87 mm	36 mm	19 mm	15 mm	FM Approved, Pipe Hanger Components, VdS G4050054
FCS0100M8	597963	85 mm	36 mm	19 mm	13 mm	VdS G4050054
FCS0125M10	597971	91 mm	36 mm	15 mm	15 mm	FM Approved, Pipe Hanger Components, VdS G4050054
FCS0125M8	597964	89 mm	36 mm	15 mm	13 mm	VdS G4050054
FCS0150M10	597972	99 mm	41 mm	17 mm	15 mm	FM Approved, Pipe Hanger Components, VdS G4050054

Catalog Number	Article Number	A	B	C	Wrench Size	Certifications
FCS0150M8	597965	97 mm	41 mm	17 mm	13 mm	VdS G4050054
FCS0200M10	597973	114 mm	50 mm	20 mm	15 mm	FM Approved, Pipe Hanger Components, VdS G4050054
FCS0200M8	597966	112 mm	50 mm	20 mm	13 mm	VdS G4050054
FCS0250M10	597974	142 mm	68 mm	30 mm	15 mm	FM Approved, Pipe Hanger Components, VdS G4050054
FCS0300M10	597975	164 mm	83 mm	39 mm	15 mm	FM Approved, Pipe Hanger Components, VdS G4050054
FCS0400M10	597976	206 mm	112 mm	55 mm	15 mm	FM Approved, Pipe Hanger Components, VdS G4050054
FCS0500M12	597977	227 mm	114 mm	44 mm	18 mm	FM Approved, Pipe Hanger Components, VdS G4050054
FCS0600M12	597978	272 mm	146 mm	63 mm	18 mm	FM Approved, Pipe Hanger Components, VdS G4050054
FCS0800M16	597979	349 mm	184 mm	75 mm	24 mm	FM Approved, Pipe Hanger Components, VdS G4050054
FCS1000M20	597981	480 mm	279 mm	143 mm	30 mm	VdS G4050054

DIAGRAMS

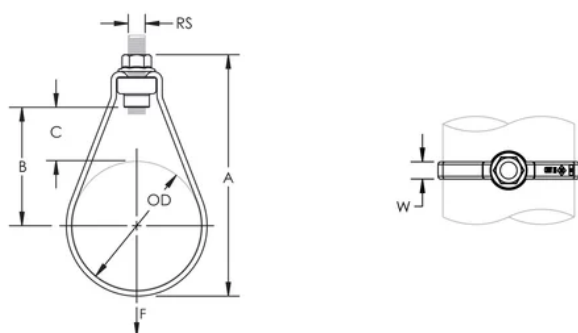

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:
nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF
TRACER