


ATCA FRONT PANEL, ST, REINFORCED, WITH SPRING LOADING

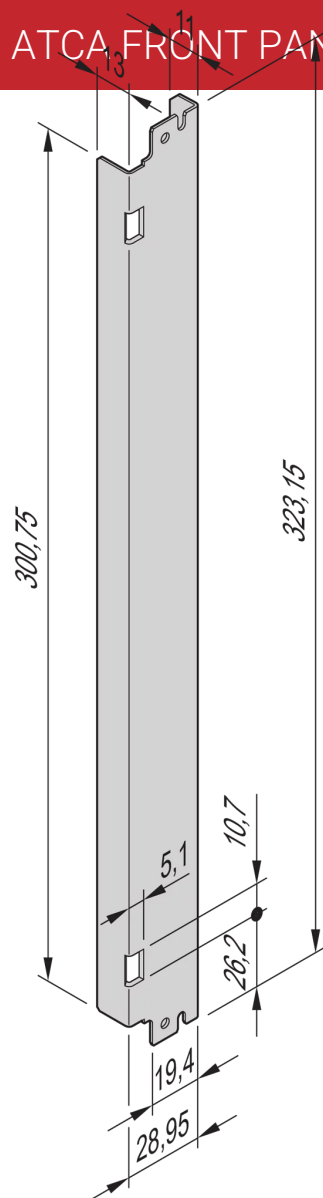

AdvancedTCA front panel for spring-loaded IEA handle with die-cast end piece.

CERTIFICATIONS

FEATURES

Configuration: Front panel with IEA handle (with/without spring loading)


SPECIFICATIONS

Accessory Type: Front panel

Table 1/2						
Catalog Number	Front Finish	Rear Finish	Material	Rack Height	Rack Width	Width (W)
31596-791	Raw	Raw	Stainless Steel	8U	6HP	29mm
31596-792	Raw	Raw	Stainless Steel	8U	6HP	29mm

Table 2/2			
Catalog Number	Depth (D)	Height (H)	Package Quantity
31596-791	1mm	323.15mm	1
31596-792	1mm	323.15mm	1

DIAGRAMS

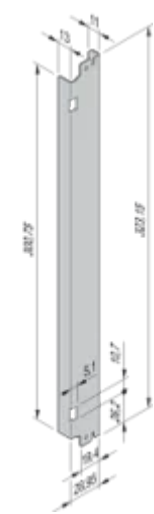

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
schroff.nvent.com

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
schroff.nvent.com

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
schroff.nvent.com

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
schroff.nvent.com



Our powerful portfolio of brands:
nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF
TRACER