



# NVENT CADDY SPEED LINK SLK WITH Y-TOGGLE



## CERTIFICATIONS



## FEATURES

- Complete system includes wire, locking device and two pre-assembled toggle end fittings
- Attaches to clearance holes in a variety of structures or hanging devices
- Ideal for supporting lighting fixtures

## SPECIFICATIONS

|                                   |                                |
|-----------------------------------|--------------------------------|
| <b>Static Load Safety Factor:</b> | 5:1                            |
| <b>Finish:</b>                    | Electrogalvanized              |
| <b>Material:</b>                  | Steel;Zinc Alloy;Polypropylene |
| <b>Complies With:</b>             | SMACNA HVAC-DCS                |

| Table 1/2         |                |                    |                  |                           |       |      |
|-------------------|----------------|--------------------|------------------|---------------------------|-------|------|
| Catalog Number    | Article Number | Wire Rope Diameter | Wire Rope Length | Wire Rope "Y" Length (YL) | A     | B    |
| SLK15Y300L3R<br>2 | 196648         | 1.5 mm             | 3m               | 0.3m                      | 39 mm | 5 mm |
| SLK15Y500L3       | 196528         | 1.5 mm             | 3m               | 0.5m                      | 39 mm | 5 mm |

| Catalog Number | Article Number | Wire Rope Diameter | Wire Rope Length | Wire Rope "Y" Length (YL) | A     | B    |
|----------------|----------------|--------------------|------------------|---------------------------|-------|------|
| SLK2Y300L7     | 196556         | 2 mm               | 7m               | 0.3m                      | 42 mm | 8 mm |
| SLK2Y500L3     | 196554         | 2 mm               | 3m               | 0.5m                      | 42 mm | 8 mm |

Table 2/2

| Catalog Number | Article Number | Static Load (F) | Packing Quantity |
|----------------|----------------|-----------------|------------------|
| SLK15Y300L3R2  | 196648         | 195N            | 2.0000           |
| SLK15Y500L3    | 196528         | 195N            | 1.0000           |
| SLK2Y300L7     | 196556         | 440N            | 1.0000           |
| SLK2Y500L3     | 196554         | 440N            | 1.0000           |


**Thickness (T):** 12.5 mm

**Width (W):** 19 mm

**Height (H):** 55 mm

**Angle (a):** 90 ° Max

## DIAGRAMS

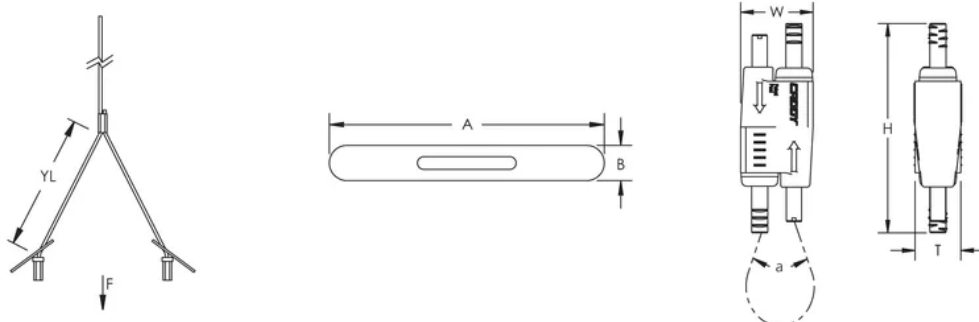

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

**North America**

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical Support

**Europe**

Netherlands:

+31 800-0200135

France:

+33 800 901 793

**Europe**

Germany:

800 1890272

Other Countries:

+31 13 5835404

**APAC**

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:  
**nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF**  
**TRACER**