

FRONT PANEL, SHIELDED, BOTTOM HINGED

U-profile front panel bottom hinged for textile gasket.



CERTIFICATIONS



FEATURES

U-profile front panel can be unhinged at 135° (not RatiopacPRO) opening angle

Enables mounting on horizontal rails

Shielded, U front panel with textile EMC gasket

Suitable for sub racks (EuropacPRO) and cases (RatiopacPRO, PropacPRO, CompacPRO)

SPECIFICATIONS

Accessory Type: Front panel

Table 1/3

Catalog Number	Type	Mounting	EMC Shielding	EMC Gasket Type	Material	Front Finish
20848-608	Front Panel without Handle	Hinged, Bottom	No (Retrofittable)	Textile	Aluminum	Anodized
20848-599	Front Panel without Handle	Hinged, Bottom	No (Retrofittable)	Textile	Aluminum	Anodized
20848-600	Front Panel without Handle	Hinged, Bottom	No (Retrofittable)	Textile	Aluminum	Anodized

Catalog Number	Type	Mounting	EMC Shielding	EMC Gasket Type	Material	Front Finish
20848-601	Front Panel without Handle	Hinged, Bottom	No (Retrofittable)	Textile	Aluminum	Anodized
20848-605	Front Panel without Handle	Hinged, Bottom	No (Retrofittable)	Textile	Aluminum	Anodized
20848-606	Front Panel without Handle	Hinged, Bottom	No (Retrofittable)	Textile	Aluminum	Anodized
20848-607	Front Panel without Handle	Hinged, Bottom	No (Retrofittable)	Textile	Aluminum	Anodized
20848-604	Front Panel without Handle	Hinged, Bottom	No (Retrofittable)	Textile	Aluminum	Anodized
20848-602	Front Panel without Handle	Hinged, Bottom	No (Retrofittable)	Textile	Aluminum	Anodized
20848-603	Front Panel without Handle	Hinged, Bottom	No (Retrofittable)	Textile	Aluminum	Anodized
20848-696	Front Panel without Handle	Hinged, Bottom	No (Retrofittable)	Textile	Aluminum	Anodized

Table 2/3						
Catalog Number	Rear Finish	Treated Edges	Rack Height	Height (H)	Rack Width	Width (W)
20848-608	Conductive	No	3U	128.4mm	28HP	141.9mm
20848-599	Conductive	No	3U	128.4mm	42HP	213mm
20848-600	Conductive	No	3U	128.4mm	63HP	319.7mm
20848-601	Conductive	No	3U	128.4mm	84HP	426.4mm
20848-605	Conductive	No	4U	172.9mm	42HP	213mm
20848-606	Conductive	No	4U	172.9mm	63HP	319.7mm
20848-607	Conductive	No	4U	172.9mm	84HP	426.4mm
20848-604	Conductive	No	6U	261.8mm	84HP	426.4mm
20848-602	Conductive	No	6U	261.8mm	42HP	213mm
20848-603	Conductive	No	6U	261.8mm	63HP	319.7mm
20848-696	Conductive	No	6U	261.8mm	28HP	141.9mm


Table 3/3			
Catalog Number	Complies With	Package Quantity	Finish
20848-608	IEC 60297-3-101, IEEE 1101.1/10	1	Anodized, Passivated
20848-599	IEC 60297-3-101, IEEE 1101.1/10	1	Anodized, Passivated

Catalog Number	Complies With	Package Quantity	Finish
20848-600	IEC 60297-3-101, IEEE 1101.1/10	1	Anodized, Passivated
20848-601	IEC 60297-3-101, IEEE 1101.1/10	1	Anodized, Passivated
20848-605	IEC 60297-3-101, IEEE 1101.1/10	1	Anodized, Passivated
20848-606	IEC 60297-3-101, IEEE 1101.1/10	1	Anodized, Passivated
20848-607	IEC 60297-3-101, IEEE 1101.1/10	1	Anodized, Passivated
20848-604	IEC 60297-3-101, IEEE 1101.1/10	1	Anodized, Passivated
20848-602	IEC 60297-3-101, IEEE 1101.1/10	1	Anodized, Passivated
20848-603	IEC 60297-3-101, IEEE 1101.1/10	1	Anodized, Passivated
20848-696	IEC 60297-3-101, IEEE 1101.1/10	1	Anodized, Passivated

ADDITIONAL PRODUCT DETAILS

Front panel can be removed in opened position (> 135°).

DIAGRAMS

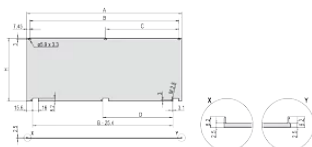

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
schroff.nvent.com

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
schroff.nvent.com

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
schroff.nvent.com

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
schroff.nvent.com



Our powerful portfolio of brands:
nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF
TRACER