



NVENT CADDY MACROFIX PLUS NI EZ WITH EASY CLOSURE



CERTIFICATIONS



FEATURES

Contains easy closing mechanism

Plastic washers help prevent crushing the CPVC or plastic pipe and assure a floating fit

Flared edges and specially designed welding area help protect CPVC piping

Ideal for installations where space is limited and require services to be ran close to the attachment surface

Suitable for 3/4" - 2" (20 - 50 DN) steel sprinkler pipe

Eliminates the need to seismically brace when drops are kept within 6" (150 mm) of the attachment surface

Combo head bolt works with slotted, hex, or Phillips drivers

Conforms with Manufacturers Standardization Society (MSS) SP-58 (Type 12)

SPECIFICATIONS

Finish: Electrogalvanized

Material: Steel


Table 1/2

Catalog Number	Article Number	Pipe Size	NB/DN	Outer Diameter (OD)	Rod Size (RS)	Width (W)
MPZ020	595052	1/2"	15	20.0 - 21.3 mm	10	30 mm
MPZ025	595053	3/4"	20	25.0 - 26.9 mm	10	30 mm
MPZ032	595054	1"	25	32.0 - 33.7 mm	10	30 mm
MPZ040	595056	1 1/4"	32	40.0 - 42.4 mm	10	30 mm
MPZ050	595057	1 1/2"	40	48.3 - 50 mm	10	30 mm
MPZ063	595059	2"	50	60.3 - 63 mm	10	30 mm
MPZ075	595061	2 1/2"	65	75.0 - 76.1 mm	10	30 mm
MPZ090	595062	3"	80	88.9 - 90 mm	10	30 mm
MPZ110	595063	4"	100	110.0 - 114.3 mm	10	30 mm

Table 2/2

Catalog Number	Article Number	Thickness (T)	Static Load (F)	Certifications
MPZ020	595052	1.5 mm	1125N	AON Fire Protection, BB019, pipe hangers
MPZ025	595053	1.5 mm	1125N	AON Fire Protection, Macrofix Plus NI EZ, FM Approved, Pipe Hanger Components
MPZ032	595054	1.5 mm	1125N	AON Fire Protection, Macrofix Plus NI EZ, FM Approved, Pipe Hanger Components
MPZ040	595056	1.5 mm	1125N	AON Fire Protection, Macrofix Plus NI EZ, FM Approved, Pipe Hanger Components
MPZ050	595057	2 mm	1725N	AON Fire Protection, Macrofix Plus NI EZ, FM Approved, Pipe Hanger Components
MPZ063	595059	2 mm	1725N	AON Fire Protection, Macrofix Plus NI EZ, FM Approved, Pipe Hanger Components
MPZ075	595061	2 mm	1725N	
MPZ090	595062	2 mm	1725N	
MPZ110	595063	2.5 mm	2000N	

DIAGRAMS

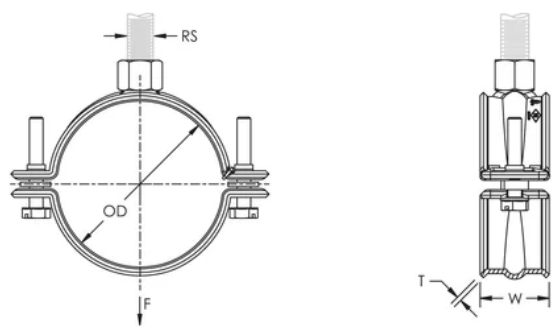

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:
nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF
TRACER